


### 5W GU10 LED Dimmable



\*Image shows GU5WW

MLA part code	GU5DWW	GU5DCW	GU5DDL
Description	GU10 LED dimmable lamp		
Finish	Clear		
Nett weight (kg)	0.05	0.05	0.066
Wattage (W)	5		
Lamp Base	GU10		
Lumens (lm)	370	420	400
Efficacy (lm/W)	71	82	80
CCT	2800K	4000K	6000K
LED Colour	Warm white	Cool white	Daylight
CRI	>80		
Overall dimensions (mm)	Diameter: 50 Height: 53		
Beam angle (°)	38		
P.F	0.7	0.7	0.7
Operating current (A)	0.032		
Input voltage	Mains 230V 50Hz		
Construction body	Glass		
Life span (Hrs)	25,000		
Warranty	2 Years		
Dimmable	Yes		
Origin of Manufacture	China		
Declaration of Conformity (held on file)	Yes		
Manufactured in accordance with	EN 60432		
EAN	5055832948070	5055832948186	5055832956624

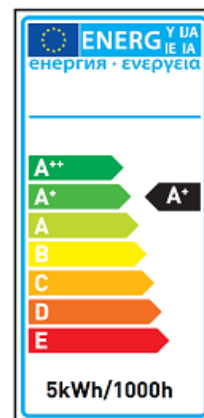