


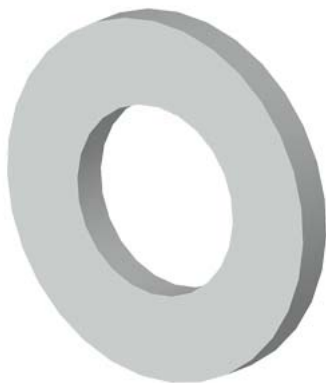

Washer ISO 7089, 10 mm, 140 HV, 1 pack = 50 units

Model	
product brand name	SIVACON S4
product designation	washer
design of the product	DIN 125, M10
type of hole	round
General technical data	
surface processing	galvanically/electrolytically zinc-plated
product feature	
• chamfered	No
• hardened	No
• with serration	No
internal diameter of the washer	10.5 mm
outer diameter of the washer	20 mm
suitable for screw dimension (metric)	10 mm
material	steel
material thickness	2 mm
Approvals Certificates	
General Product Approval	other

[Miscellaneous](#)



[Miscellaneous](#)

other	Environment
-------	-------------

[Confirmation](#)

[Environmental Con-
firmations](#)

[Environmental Con-
firmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8PQ9500-0BA67>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8PQ9500-0BA67>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8PQ9500-0BA67

last modified:

5/1/2025 

