
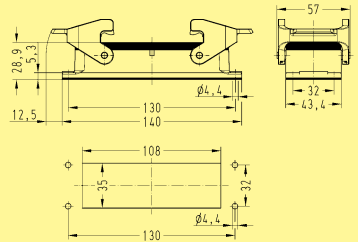

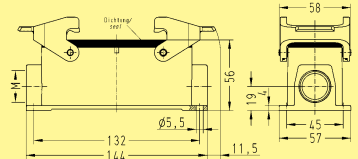

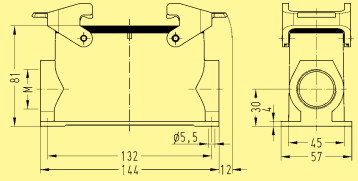

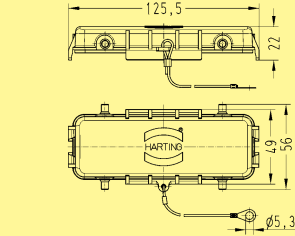

 


Metal hoods/housings for industrial applications / 2 lever locking system

Identification	Part number		Cable entry metric	Drawing	Dimensions in mm
	Low construction	High construction			
Housings, bulkhead mounting 	<b>09 30 024 0301</b>			 <p>Panel cut out</p>	
Housings, surface mounting side entry 	<b>19 30 024 1231</b> <b>19 30 024 1271</b>		<b>1 x 25</b> <b>2 x 25</b>	 <p>Blind way for one cable entry</p>	
side entry 		<b>19 30 024 0232</b> <b>19 30 024 0272</b> <b>19 30 024 0273</b>	<b>1 x 32</b> <b>2 x 32</b> <b>2 x 40</b>	 <p>Blind way for one cable entry</p>	
Protection covers 	metal <b>09 30 024 5425</b>	metal <b>09 30 024 5425</b>			
Protection covers 	plastic <b>09 30 024 5405</b>	plastic <b>09 30 024 5405</b>			

Han Hoods Housings