


INSTRUCTIONS

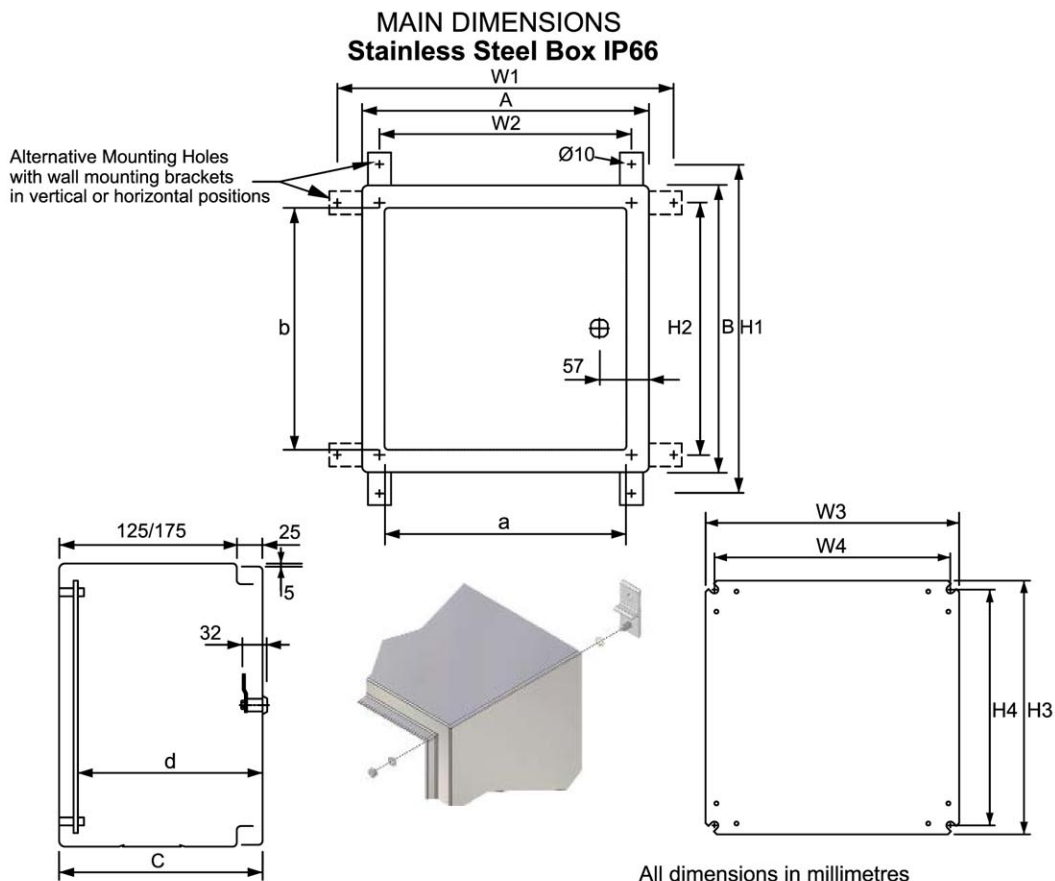

TYPE	OVERALL SIZE			OPENING DEPTH			MOUNTING HOLE POSITIONS				MOUNTING PLATE HOLE SIZE				LOCKS	WEIGHT kg	ORDER NO AISI 304	ORDER NO AISI 316
	A	B	C	a	b	d	W1	W2	H1	H2	W3	H3	W4	H4				
SBOX 2.2-150	200	200	150	150	150	135	240	160	240	160	148	148	125	125	1	4.56	60600	61100
SBOX 2.3-150	200	300	150	150	250	135	240	160	340	260	148	248	125	225	1	5.78	60610	61110
SBOX 2.5.3-150	250	300	150	200	250	135	290	210	340	260	198	248	175	225	1	6.60	60620	61120
SBOX 3.3-150	300	300	150	250	250	135	340	260	340	260	248	248	225	225	1	7.42	60630	61130
SBOX 3.3-200	300	300	200	250	250	185	340	260	340	260	248	248	225	225	1	9.16	60640	61140
SBOX 3.4-150	300	400	150	250	350	135	340	260	440	360	248	348	225	325	1	9.06	60650	61150
SBOX 3.4-200	300	400	200	250	350	185	340	260	440	360	248	348	225	325	1	10.93	60660	61160
SBOX 4.3-150	400	300	150	350	250	135	440	360	340	260	348	248	325	225	1	9.06	60670	61170
SBOX 4.3-200	400	300	200	350	250	185	440	360	340	260	348	248	325	225	1	10.93	60680	61180
SBOX 4.4-150	400	400	150	350	350	135	440	360	440	360	348	348	325	325	1	11.13	60690	61190
SBOX 4.4-200	400	400	200	350	350	185	440	360	440	360	348	348	325	325	1	13.13	60700	61200
SBOX 4.5-150	400	500	150	350	450	135	440	360	540	460	348	448	325	425	1	13.20	60710	61210
SBOX 4.5-200	400	500	200	350	450	185	440	360	540	460	348	448	325	425	1	15.33	60720	61220
SBOX 4.5-250	400	500	250	350	450	235	440	360	540	460	348	448	325	425	1	14.12	60725	61225
SBOX 4.6-200	400	600	200	350	550	185	440	360	640	560	348	548	325	525	2	17.52	60730	61230
SBOX 4.6-250	400	600	250	350	550	235	440	360	640	560	348	548	325	525	2	16.45	60735	61235
SBOX 4.7-200	400	700	200	350	650	185	440	360	740	660	348	648	325	625	2	19.72	60740	61240
SBOX 5.6-200	500	600	200	450	550	185	540	460	640	560	448	548	425	525	2	20.58	60750	61250
SBOX 5.7-200	500	700	200	450	650	185	540	460	740	660	448	648	425	625	2	23.20	60760	61260
SBOX 5.7-250	500	700	250	450	650	235	540	460	740	660	448	648	425	625	2	22.38	60765	61265
SBOX 6.4-200	600	400	200	550	350	185	640	560	440	360	548	348	525	325	1	17.52	60770	61270
SBOX 6.4-300	600	400	300	550	350	285	640	560	440	360	548	348	525	325	1	17.73	60780	61280
SBOX 6.5-200	600	500	200	550	450	185	640	560	540	460	548	448	525	425	1	20.58	60785	61285
SBOX 6.6-200	600	600	200	550	550	185	640	560	640	560	548	548	525	525	2	23.63	60790	61290
SBOX 6.6-300	600	600	300	550	550	285	640	560	640	560	548	548	525	525	2	24.35	60800	61300
SBOX 6.7-200	600	700	200	550	650	185	640	560	740	660	548	648	525	625	2	26.68	60810	61310
SBOX 6.8-200	600	800	200	550	750	185	640	560	840	760	548	748	525	725	2	29.74	60820	61320
SBOX 6.8-250	600	800	250	550	750	235	640	560	840	760	548	748	525	725	2	29.17	60830	61330
SBOX 6.8-300	600	800	300	550	750	285	640	560	840	760	548	748	525	725	2	30.97	60840	61340
SBOX 6.10-200	600	1000	200	550	950	185	640	560	1040	960	548	948	525	925	2	35.84	60850	61350
SBOX 6.12-200	600	1200	200	550	1150	185	640	560	1040	1160	548	1148	525	1125	3	41.0	60855	61355
SBOX 8.8-200	800	800	200	750	750	185	840	760	840	760	748	748	725	725	2	37.55	60860	61360
SBOX 8.8-300	800	800	300	750	750	285	840	760	840	760	748	748	725	725	2	39.30	60870	61370
SBOX 8.10-200	800	1000	200	750	950	185	840	760	1040	960	748	948	725	925	2	45.37	60880	61380
SBOX 8.10-250	800	1000	250	750	950	235	840	760	1040	960	748	948	725	925	2	45.32	60890	61390
SBOX 8.10-300	800	1000	300	750	950	285	840	760	1040	960	748	948	725	925	2	47.63	60900	61400
SBOX 8.12-200	800	1200	200	750	1150	185	840	760	1240	1160	748	1148	725	1125	3	50.83	60905	61405
SBOX 8.12-250	800	1200	250	750	1150	235	840	760	1240	1160	748	1148	725	1125	3	53.39	60906	61406
SBOX 8.12-300	800	1200	300	750	1150	285	840	760	1240	1160	748	1148	725	1125	3	55.96	60910	61410
SBOX 10.10-200	1000	1000	200	950	950	185	1040	960	1040	960	948	948	925	925	2	52.54	60915	61415
SBOX 10.10-300	1000	1000	300	950	950	285	1040	960	1040	960	948	948	925	925	2	57.67	60920	61420
SBOX 10.12-300	1000	1200	300	950	950	285	1040	960	1240	1160	948	1148	925	1125	3	67.71	60930	61430