

## Han TC300 male contact axial 95-120mm<sup>2</sup>

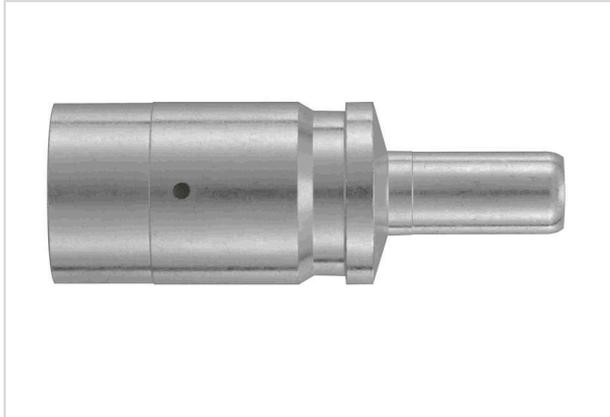


Image is for illustration purposes only. Please refer to product description.

Part number	09 11 000 6539
Specification	Han TC300 male contact axial 95-120mm <sup>2</sup>
HARTING eCatalogue	<a href="https://harting.com/09110006539">https://harting.com/09110006539</a>

### Identification

Category	Contacts
Series	TC 300
Type of contact	Axial screw contact

### Version

Termination method	Axial screw termination
Gender	Male
Manufacturing process	Turned contacts

### Technical characteristics

Conductor cross-section	95 ... 120 mm <sup>2</sup>
Rated current	≤300 A
Contact resistance	≤0.3 mΩ
Stripping length	19 ... 20 mm
Tightening torque	14 Nm @ 95 mm <sup>2</sup> 16 Nm @ 120 mm <sup>2</sup>
Wrench size	5 20
Limiting temperature	-40 ... +125 °C
Mating cycles	≥500

### Material properties

Material (contacts)	Copper alloy
Surface (contacts)	Silver plated



**Pushing Performance**  
Since 1945

## Material properties

RoHS	compliant
ELV status	compliant
China RoHS	e
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained
REACH SVHC substances	Not contained
California Proposition 65 substances	Not contained

## Specifications and approvals

Specifications	IEC 60664-1 IEC 61984
----------------	--------------------------

## Commercial data

Packaging size	1
Net weight	73.78 g
Country of origin	Romania
European customs tariff number	85359000
GTIN	5713140188501
eCl@ss	27440204 Contact for industrial connectors
ETIM	EC000796
UNSPSC 24.0	39121522