


Cable grommet, natural, 2000pcs.

Art.-No. 631-08229 | HV4822-PVC-FR-NA | 

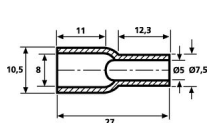

- Protects effectively against spraying water
- Flexible and easy to apply
- High resistance to chemicals and environmental influences


RoHS 

More products in this product group:

[For blade receptables and terminals >](#)

Application	The protective push-on caps and elbow grommets are specially constructed to insulate and protect flat pin bushings. They are used in all areas of automotive electronics and connection technology.
Cable ø max	5.0 mm
Cable ø min	2.0 mm
Colour	Natural (NA)
Material	Polyvinylchloride, flame retardant (PVC-FR)
PART DESCRIPTION	HV4822-PVC-FR-NA
Pack Content	2000 pcs.
Package Content packed in	pcs.
Product Family	HV4822
Product Group	For blade receptables and terminals
Type	HV4822
Variant	Open


Product Dimensions

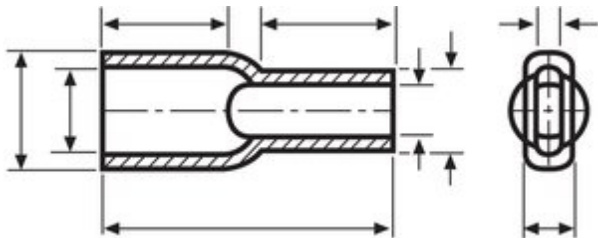

ø (D2)	5.0 mm
Diameter (D)	8.0 mm
Outside ø (OD)	10.5 mm
Outside ø (OD2)	7.5 mm
Shore Hardness A	55±5

Specifications

ELV compliant (Article 4 - 2)	YES
Flammability	UL 94 V0
Hazardous Goods	No
Nato number	5975-12-315-1708
Operating Temperature	-30 °C to +60 °C
ROHS compliant	Yes
Specifications	

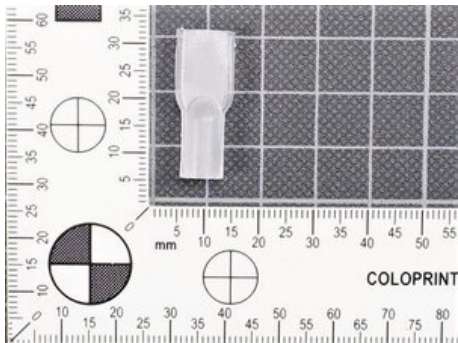

GTIN-13 / EAN	4031026185804
Packaging 1 - Height (m)	0.09 m
Packaging 1 - Length (m)	0.21 m
Packaging 1 - Qty	2000
Packaging 1 - Type	bag
Packaging 1 - Volume (m³)	0.005859 m³
Packaging 1 - Weight (kg)	1.762 kg
Packaging 1 - Width (m)	0.31 m

More Information