



SIVACON, door half, left, with ventilation openings, IP40, H: 2000 mm, W: 500 mm, RAL 7035, protection class 1

| Model                               |                           |                   |
|-------------------------------------|---------------------------|-------------------|
| product brand name                  | SIVACON                   |                   |
| product designation                 | Door half                 |                   |
| design of the product               | With ventilation openings |                   |
| design of the surface               | Powder-coated             |                   |
| design of the product EMC version   | No                        |                   |
| Protection class                    |                           |                   |
| protection class IP                 | IP40                      |                   |
| operating resource protection class | safety class 1            |                   |
| Appearance                          |                           |                   |
| RAL color number                    | 7035                      |                   |
| color                               | light grey                |                   |
| Product details                     |                           |                   |
| product component                   |                           |                   |
| • ventilation                       | Yes                       |                   |
| • viewing door                      | No                        |                   |
| • door for disconnecter lock        | No                        |                   |
| Mechanical Design                   |                           |                   |
| height                              | 2 000 mm                  |                   |
| width                               | 500 mm                    |                   |
| opening direction of the door       | left                      |                   |
| material                            | steel                     |                   |
| Approvals Certificates              |                           |                   |
| General Product Approval            |                           | Test Certificates |
|                                     |                           | other             |



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

|       |             |
|-------|-------------|
| other | Environment |
|-------|-------------|

[Miscellaneous](#)

Siemens  
EcoTech



[Environmental Confirmations](#)

| Further information                                                                                                                                                     |
|-------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| Information on the packaging<br><a href="https://support.industry.siemens.com/cs/ww/en/view/109813875">https://support.industry.siemens.com/cs/ww/en/view/109813875</a> |

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1050-2UT25-2BA2>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1050-2UT25-2BA2>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=8MF1050-2UT25-2BA2](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1050-2UT25-2BA2)

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

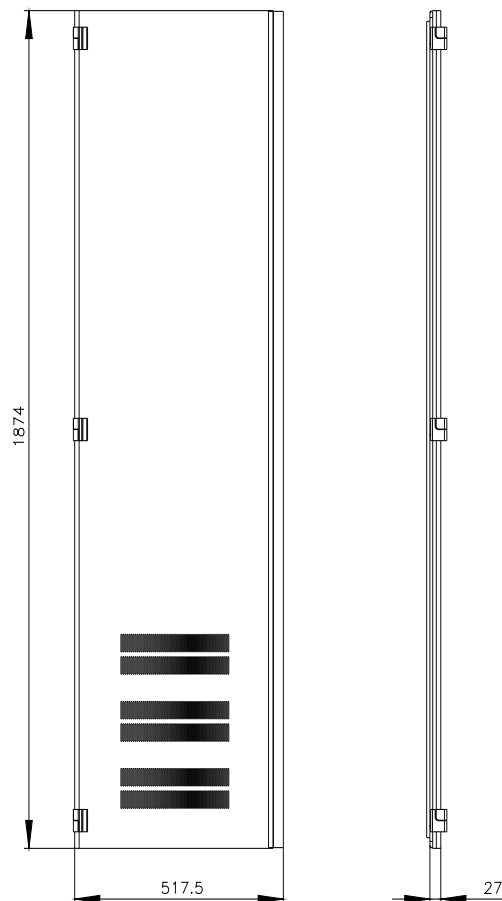

last modified:

4/13/2025 

