


Pre-printed cable markers : WIC1-3

Clip On Cable Marker 2-2.8mm orange Imprint 3

Article number: 561-01633

 Add to watchlist

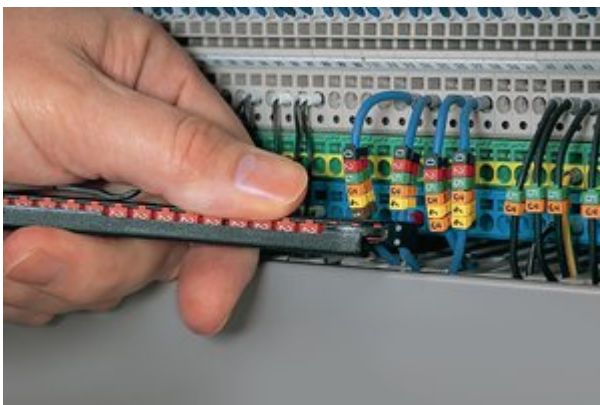

 Images (11)

 Downloads

Access Denied
(policy_denied)

Your system policy
has denied access to
the requested URL.

For assistance, contact
your network support
team.

Your request was
categorized by Blue Coat
Web Filter as 'Mixed
Content/Potentially
Adult;Audio/Video Clips'.
If you wish to question or
dispute this result, please

Features

Contact 

- Fast and easy to use pre-printed nylon snap-on marker
- Ideal where termination is completed or for maintenance and repair
- Markers lock together to give perfect text alignment
- Vibration resistant markers, WIC markers lock onto wire and cable tightly
- WIC tool holds 20 WIC markers in all four sizes
- Gripping system locks markers onto wire and resists rotation
- Popular 2 digit markings such as L1, L2, L3, PE are available in yellow or colour code
- Dispenser colour denotes marker size: WIC0 (green), WIC1 (red), WIC2 (blue), WIC3 (yellow)
- Two accessories available to identify cables from 6 mm² up to 25 mm² (WICA-AC10-25) and up to 95 mm² (WICA-ACT-BK)

Certifications & Approvals



Application

The WIC range of pre-printed cable markers easily snap onto cables and wires. The WIC tool ensures an easy application of the markers – simply insert the markers into the tool, slide down and press the markers onto the wire while twisting. Markers for fibre cables should be applied by hand.

All markers come with a locking mechanism to ensure perfect text alignment.

The two WICA accessories are ideal for marking cables of larger diameters (6mm-95mm2).

More products in this product group


Pre-printed cable markers >

Base Data

Application Tool	WIC Tool
Colour	Orange (OG)
Fixation Method	Plug in
Marking Text	3
Pack Cont.	1000 pcs.
Package Content in	box
PART DESCRIPTION	WIC1-3-PA66-OG
Product Family	WIC, snap on
Product Group	Pre-printed cable markers
Short Description	Clip On Cable Marker 2-2.8mm orange Imprint 3
Variant	Other
With label space	No

Product Dimensions

Contact 

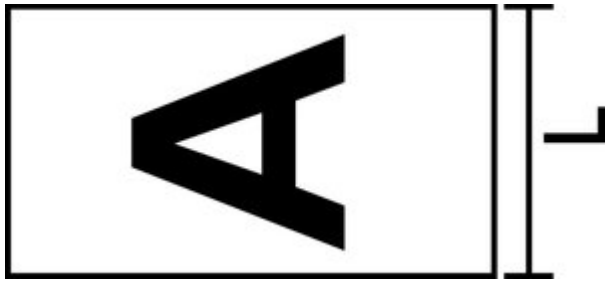

Bundle \varnothing max.	2.80 mm
Bundle \varnothing min.	2.00 mm
Height (H)	6.40 mm
Length (L)	3.0 mm
Outside \varnothing max.	.110 "
Outside \varnothing min.	.078 "
Print Method	Hotfoil printing
Width (W)	5.00 mm
Wire Size Range (mm ²)	0.50-1.50 mm ²

Material and Specifications

ELV compliant (Article 4 - 2)	YES
Flammability	UL 94 V0
Halogenfree	Yes
Hazardous good	No
Material	Polyamide 6.6 (PA66)
Operating Temperature - °C	-40 °C to +85 °C
Specifications	HF ✓ RoHS ✓
Specifications	EN 60062, IEC 304

Logistics and Packaging

More Information

ETIM 7.0 Key	EC001530
--------------	----------

Accessories

Contact 

WIC Tool

561-00001

Pre-printed cable markers



Sample Pack WIC

561-00002



WICA-ACT-BK

561-06000

Pre-printed cable markers



WICA-AC10-25

561-06001

Pre-printed cable markers



Similar products



WIC1-BROWN

561-01751

Pre-printed cable markers



WIC1-RED

561-01752

Pre-printed cable markers



WIC1-ORANGE

561-01753

Pre-printed cable markers



WIC1-GREEN

561-01755

Pre-printed cable markers



WIC1-GREY

561-01758

Pre-printed cable markers



WIC2-BROWN

561-02751

Pre-printed cable markers



Show all

Contact