

SylRound Superia

SYLROUND SUPERIA LED 195 15W 840

0053383



Range features

- Integrated LED downlight with high lumen output
- IP44 protection – ideal for bathrooms and corridors
- Frosted lens for anti-glare
- Made from durable polycarbonate with aluminium thermal heat dissipater
- Includes LED Driver 350mA
- Small recess depth



PRODUCT OVERVIEW

Ordering number	0053383
Light colour	Cool White
Technology	LED
Average life (Rated) (h)	50000
EAN code	5410288533834
Certifications	EC
Mount	Ceiling recessed
Housing	Polycarbonate
CRI (Ra)	80
LOR (%)	100
Efficacy (Rated) (lm/w)	75
Voltage (V)	220-240
Colour	White
IP rating	44
IK rating	02

SylRound Superia

SYLROUND SUPERIA LED 195 15W 840

0053383

DATA TABLE

General data

Technology	LED
Ordering number	0053383
Average life (Rated) (h)	50000
EAN code	5410288533834
Certifications	EC
Mount	Ceiling recessed
Long description	Integrated LED downlight with high lumen output. IP44 protection – ideal for bathrooms and corridors. Frosted lens for anti-glare. Made from durable polycarbonate with aluminium thermal heat dissipater. Includes LED Driver 350mA. Small recess depth
Product name	SYLROUND SUPERIA LED 195 15W 840
Control gear type	External
Environment	Interior
General application	Residential accent downlighting
Housing	Polycarbonate

Optical data

Light colour	Cool White
CRI (Ra)	80
LOR (%)	100
Luminous flux (Nominal) (lm)	1126
Distribution type	Direct

Electrical data

Efficacy (Rated) (lm/w)	75
Voltage (V)	220-240
Drive current (mA)	350mA
Electrical protection	CLASS II

SylRound Superia

SYLROUND SUPERIA LED 195 15W 840

0053383

Physical data


Weight (kg)	0.5
Colour	White
Lamp included	Yes
Height (mm)	51
Width (mm)	193
Length (mm)	193
IP rating	44
IK rating	02
Cutout diameter (mm)	175 ø
Cutout shape	Round
Recessed depth (mm)	51
Diffuser finish	Frosted
Diffuser material	Polycarbonate
Reflector material	Bright Aluminium Reflector

SylRound Superia

SYLROUND SUPERIA LED 195 15W 840

0053383

TECHNICAL DRAWINGS

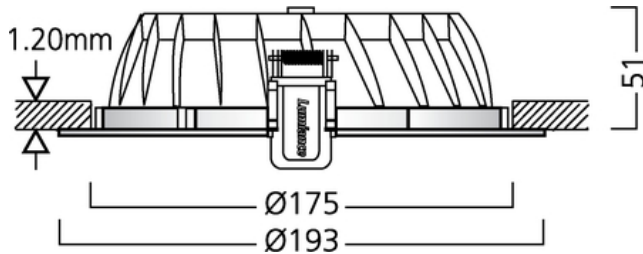

ENERGY LABEL

