


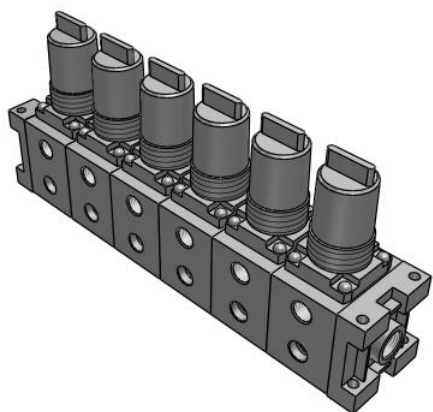


ARM2500/3000, Modular Style, Regulator Manifold Series ARM2500-06A-02

Datasheet

General series information

 
- Regulator manifold, modular type
- Metric type threads
- Optimal for central pressure control
- One-touch lock system
- Maximum operating pressure: 1.0MPa



Standard specifications

Size	25 (Size 2500, Flow 750NI/min)
Stations	6 Stations
Piping Specification	A (IN: Common)
Thread	Rc(PT)
Port Size	02 (PT 1/4)
Accessory	None
Maximum temperature of pressure medium	60 °C
Minimum temperature of pressure medium	-5 °C (with no freezing)
Maximum operating pressure	0.8 MPa
Proof pressure	1.2 MPa
Set pressure range	0.05 - 0.7 MPa
Applicable fluid	Air
Relief mechanism	Relieving type
Weight	1.900 Kg

Dimensions

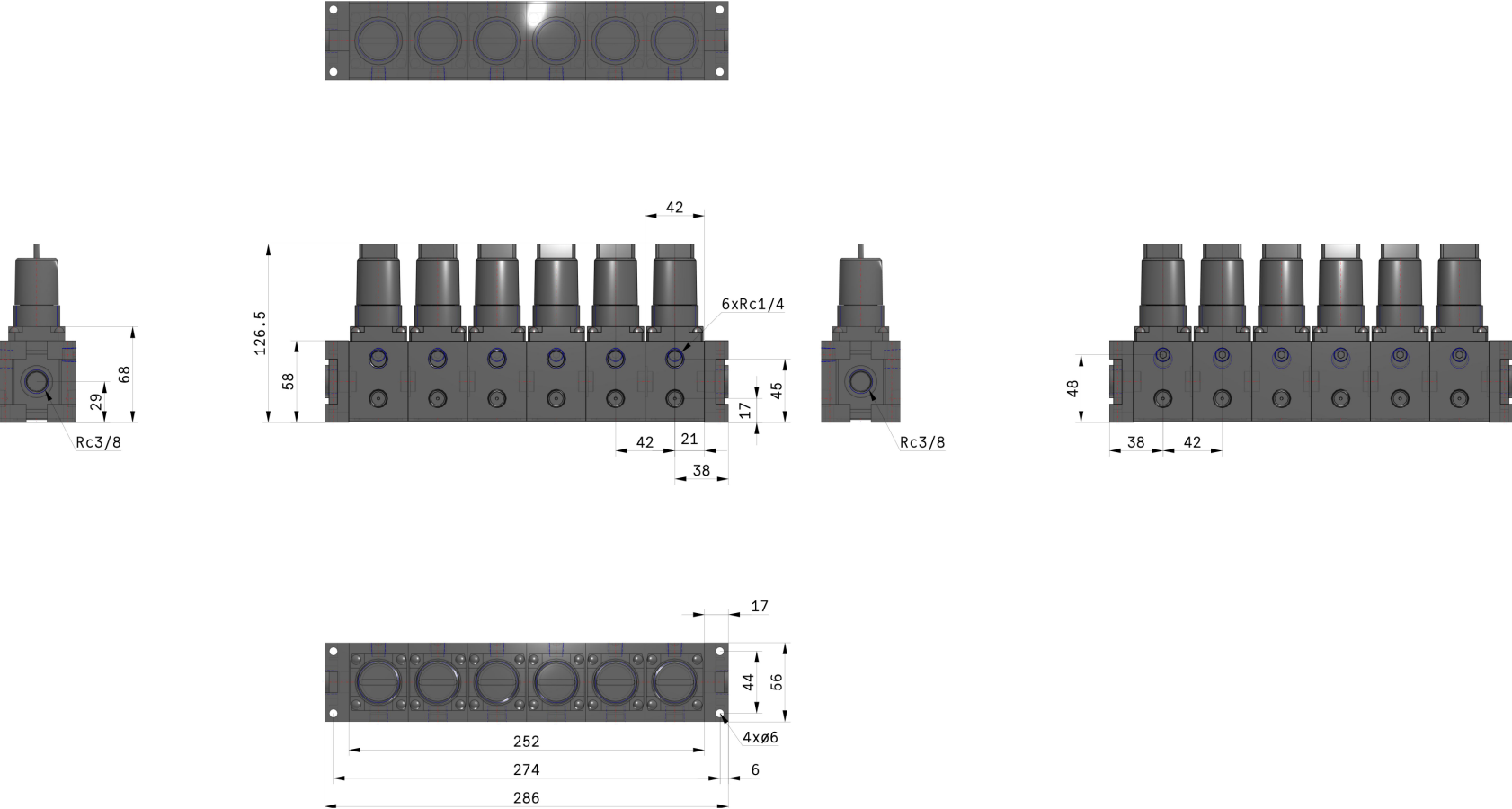

Specifications are subject to change without prior notice and any obligation on the part of the manufacturer.

Additional information

Catalogue

[ARM_EU.pdf](#)

Operation manuals

[OM_ARM2500_3000_OMD0094EN.pdf](#)