


## MANUAL OPERATED STENCIL PRINTER FOR SMD TECPRINT 500

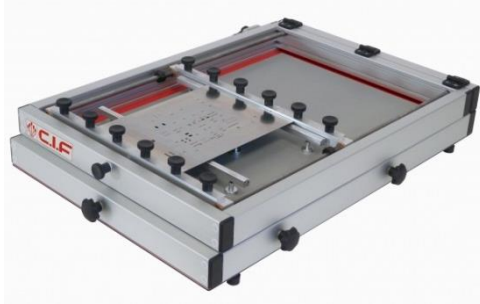

Reference: V900016

### NEW MODEL

Create your printing in a short time and for low price!

Compact model

FLEXIBLE • AUTO - TENSIONER SYSTEM • ACCURATE

- Stencil max: 210 x 320 mm
- PCB max: 200 x 270 mm
- Compatible with double reflow process (Height available: 25 mm)
- Very easy to place the stencil. No extra frame, auto-tensioner system
- Immediate adjustment in X, Y and  $\theta$  of the stencil  $\pm 7.0$  mm
- Delivered with a lot of accessories.

TECPRINT 500 is a new manual operated stencil printer

Fixing a stencil is fast and easy with our auto-tensioner system.

The stencil printer can be used for one as well as two sided PCB's, even if there are already components on one side (height available 25 mm)

### Technical specifications

Model	TECPRINT 500
Reference	V900016
Max stencil	210 x 320 mm
Mini stencil	50 x 50 mm
Max PCB	200 x 270 mm
Mini PCB	30 x 50 mm
Dimensions	315 x 550 x 200 mm
Net weight	5.5 Kg

The stencil printer TECPRINT 500 (ref. V900016) is delivered complete with

- a squeegee with stainless steel blade
- 3 adjustable pins for PCB anti-buckling