



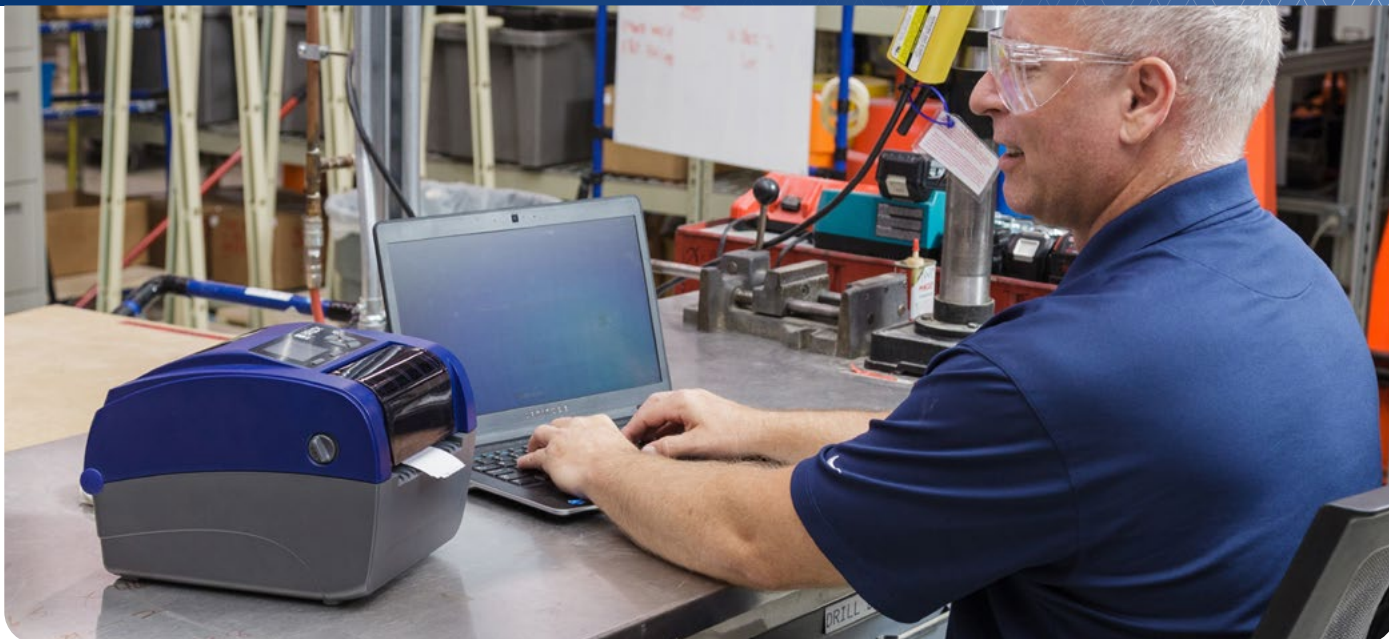

BBP12 LABEL PRINTER

Ready to print in 1-2-3

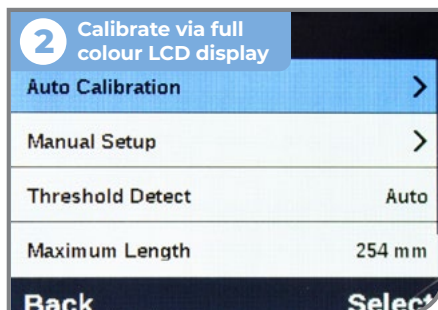

There are a dozen good reasons to choose the compact benchtop entry level BBP12 Label Printer:

- 1 Compact in size, fits on every desk
- 2 Default Ethernet Connectivity, allowing you to work in a network
- 3 Connect any universal keyboard via USB 2.0 to work in stand-alone mode
- 4 Full colour LCD Display and intuitive software interface are simple to use, so no extensive training is required
- 5 Simple calibration menu with easy 1-2-3 step printing
- 6 Prints a wide range of identification labels from 6 mm up to 112 mm wide
- 7 Standard 300 dpi print quality allowing accurate image & barcode positioning on small labels
- 8 With its powerful 32 bit processor and its extended memory it can print up to 100 mm / sec
- 9 The printer supports the industry-standard Zebra® and Eltron® programming languages
- 10 Print time and date on to your labels via the "Real time clock feature"
- 11 Best price/quality in the market for low volume printing
- 12 Comes with a free unwinder accessory to print larger label rolls

Printer



Article No.	Order Ref.	Description
322908	BBP12-EU-U-C-BWS	BBP12 Label printer 300 dpi - EU with Cutter, Unwinder and Brady Workstation Suite**
195966	BBP12-EU-U-CUTTER	BBP12 Label printer 300 dpi - EU with Cutter and Unwinder*
195566	BBP12-EU-UNWINDER	BBP12 Label printer 300 dpi - EU with Unwinder*
322905	BBP12-EU-U-BWS	BBP12 Label printer 300 dpi - EU with Unwinder and Brady Workstation Suite**
322909	BBP12-UK-U-C-BWS	BBP12 Label printer 300 dpi - UK with Cutter, Unwinder and Brady Workstation Suite**
195967	BBP12-UK-U-CUTTER	BBP12 Label printer 300 dpi - UK with Cutter and Unwinder*
195567	BBP12-UK-UNWINDER	BBP12 Label printer 300 dpi - UK with Unwinder*
322906	BBP12-UK-U-BWS	BBP12 Label printer 300 dpi - UK with Unwinder and Brady Workstation Suite**
322910	BBP12-US-U-C-BWS	BBP12 Label printer 300 dpi - US with Cutter, Unwinder and Brady Workstation Suite**
195968	BBP12-US-U-CUTTER	BBP12 Label printer 300 dpi - US with Cutter and Unwinder*
195568	BBP12-US-UNWINDER	BBP12 Label printer 300 dpi - US with Unwinder*
322907	BBP12-US-U-BWS	BBP12 Label printer 300 dpi - US with Unwinder and Brady Workstation Suite**



* BRADY WORKSTATION BASIC DESIGN:

Ships with the free Brady Workstation Basic Design suite that includes fundamental apps and features to create labels.

** BRADY WORKSTATION ADVANCED SUITE:

Product & Wire Identification, Safety & Facility Identification, or Lab Identification, enabling easy creation of a wide range of labels and signs.

Printer kits

Article No.	Order Ref.	Description
198588	BBP12-DATA Kit-EU	BBP12 Label printer 300 dpi - Datacom Kit - EU + BWS Suite
198589	BBP12-DATA Kit-UK	BBP12 Label printer 300 dpi - Datacom Kit - UK + BWS Suite
198590	BBP12-DATA Kit-US	BBP12 Label printer 300 dpi - Datacom Kit - US + BWS Suite
198591	BBP12-ELEC Kit-EU	BBP12 Label printer 300 dpi - Electrical Kit - EU + BWS Suite
198592	BBP12-ELEC Kit-UK	BBP12 Label printer 300 dpi - Electrical Kit - UK + BWS Suite
198593	BBP12-ELEC Kit-US	BBP12 Label printer 300 dpi - Electrical Kit - US + BWS Suite
198596	BBP12-LAB Kit-EU	BBP12 Label printer 300 dpi - Laboratory Kit - EU + BWS Suite
198597	BBP12-LAB Kit-UK	BBP12 Label printer 300 dpi - Laboratory Kit - UK + BWS Suite
198598	BBP12-LAB Kit-US	BBP12 Label printer 300 dpi - Laboratory Kit - US + BWS Suite

Datacom kits: This BBP12 label printer comes in a cardboard box. It ships with an unwinder, USB Cable, power cord, product CD, Quick Start Guide, Brady Workstation Suite, BPT-611-499, THT-75-427-3, BPT-5-8423-2.5, R-4900 65MMX70M / O, R-7950 65MMX70M / O, R6000HF 110MMX70M / O

Electrical kits: This BBP12 label printer comes in a cardboard box. It ships with an unwinder, USB Cable, power cord, product CD, Quick Start Guide, Brady Workstation Suite, THT-136-499-3, BPT-511-427, PS-187-2-WT-S, R4900 65mmx70m / O, R-7950 110MMX70M / O, R-6600 102MM X 74M / O

Laboratory kits: This BBP12 label printer comes in a cardboard box. It ships with an unwinder, USB Cable, power cord, product CD, Quick Start Guide, Brady Workstation Suite, THT-131-461-3, THT-156-492-3, THT-163-499-3, R7950 35mmx70m / O, R6400 65mmx70m / O, R4900 65mmx70m / O

Accessory



Article No.	Order Ref.	Description
361064	BBP12/BBP11-PLnPR	Peel and Present

Specifications

Printer	
Weight	2.50 kg
Dimensions	Size - Depth: 258 mm Size - Height: 173 mm Size - Width: 202 mm
Max. Print Width	105.60 mm
Mode of operation	Stand-Alone with external keyboard & Peripheral
Print resolution	300 dpi

Display	
Display Type	Full colour LCD display

Materials supported	
Materials	Nylon Cloth, Paper, Polyester, Polyethylene, Polyimide, Polyolefin (Sleeves), Polypropylene, Thermoplastic polyether-polyurethane, Vinyl, Vinyl Cloth, Outdoor Vinyl, Self-laminating Vinyl

Barcodes	
Barcode Type	2D and 1D (Linear)

Software & connectivity	
Connectivity	Serial, USB 2.0, Ethernet
Software Compatibility	Brady Workstation, LabelMark, CodeSoft, Windows® based driver for 3rd party software

Compliance	
Approval/Compliance	UL; cUL; CE; RoHS; EAC

