




HP5R

185 Lumens | 183 m Beam | IPX4 | Lithium Polymer or 1 × AA

PREV

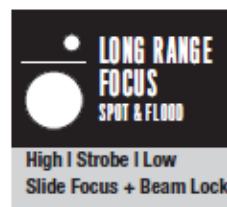

High | Strobe | Low
Slide Focus + Beam Lock

Length: 4.875" | 12.4 cm
Weight: 2.6 oz. | 74 g

2 × lithium polymer batteries
1 × AA battery

AC+DC with USB adapters

Wall mount + Speed clip

Heavy-duty sheath

Lanyard

Clam: —
Box: 19905

ANSI FL1 (Li Poly) High	Low
Lumens	185 19
Beam Distance	183m 56m
Runtime	4h 30min 14h

ANSI FL1 (Aik) High	Low
Lumens	100 12
Beam Distance	127m 45m
Runtime	2h 30min 9h

Compact in size and combining our Long Range Optic System with slide focus and a lightweight aluminum body, the HP5R is optimal for pocket carry.



Slide Focus



Lens filter kit
available



Strobe

FLEX CHARGE DUAL POWER



The HP5R includes two lithium polymer rechargeable batteries and one AA battery. The rechargeable batteries can be charged either inside or outside the torch, assuring that you're never out of power. With the AC and DC adapters connected via a USB cable (all included), charging can be done in diverse and remote locations.



RECHARGEABLE BATTERIES

Item: 19703

