
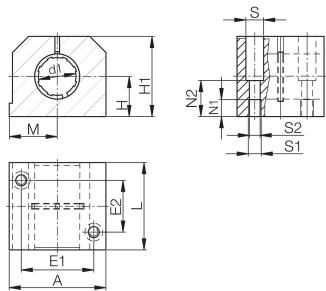


drylin® R pillow block RJUM-06

RJUM-06-20

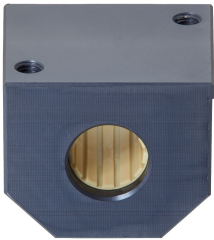

drylin® R pillow block RJUM-06

| Part number | RJUM-06-20 |
|-------------|------------|
| Ø d1        | 20 mm      |
| H1          | 50 mm      |
| A           | 60 mm      |
| M           | 30 mm      |
| E1          | 45 mm      |
| E2          | 32 mm      |
| Ø S         | 11 mm      |
| S1          | M8         |
| Ø S2        | 6.6 mm     |
| N1          | 24 mm      |
| N2          | 18 mm      |
| H Bolt      | 25 mm      |

Product description

Introducing the drylin R pillow block RJUM-06, a reliable solution for your bearing needs. This product features a durable design, ensuring long-lasting performance. Ideal for various applications, it offers a matching replacement liner for easy maintenance. Trust the drylin brand for quality and efficiency in your projects. Choose the RJUM-06 for a dependable and effective bearing solution.

Dimensions

|        |       |
|--------|-------|
| Ø d1   | 20 mm |
| H Bolt | 25 mm |
| H1     | 50 mm |
| S1     | M8    |
| M      | 30 mm |
| E1     | 45 mm |
| E2     | 32 mm |
| A      | 60 mm |
| Ø S    | 11 mm |
| L      | 54 mm |



## General properties

Sliding element material

iglidur® J

Housing material

anodised aluminium

## Certificates and standards



Additional information and diagrams

