


**push-in connector**  
**NPQM-D-Q6-E-P10**

Part number: 558761

**FESTO**

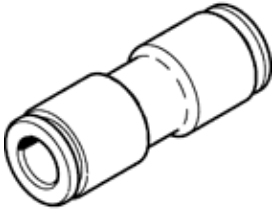

**Data sheet**

<b>Feature</b>	<b>Value</b>
Size	Standard
Nominal size	5 mm
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-20 ... 70 °C
Product weight	15 g
Pneumatic connection, port 1	For tubing outside diameter 6 mm
Pneumatic connection, port 2	For tubing outside diameter 6 mm
Materials note	Conforms to RoHS
Material housing	Nickel-plated brass
Material of tubing seal	NBR