



 
DELL ULTRASHARP 27 MONITOR | U2719D

Designed for performance



OUTSTANDING VISUALS

See details in striking clarity and with accurate colors on this 27" QHD screen.



MAXIMIZE PRODUCTIVITY

Ultrathin InfinityEdge bezel and efficiency enhancing features help you stay productive.



INNOVATIVE DESIGN

Sleek design with a thin panel profile and a compact base to free up valuable desk space.



TRUSTED RELIABILITY

World's number 1 monitor company.*
Backed by renowned Dell reliability.

Designed for performance



OUTSTANDING VISUALS

Impeccable details: See details in striking clarity. With QHD (2560x1440) resolution, you'll get 1.77 times more details than Full HD.

Color consistency comes standard: Your UltraSharp monitor is factory calibrated at 99% sRGB coverage to an accuracy of Delta-E less than 2, for precise hues right out of the box. Plus with 99% Rec709 and 85% DCI-P3 color space coverage, you'll see true-to-life colors in video formats.

Always the best view: See consistent, vibrant colors across a wide viewing angle enabled by In-Plane Switching (IPS) technology.



 
INNOVATIVE DESIGN

More room to work: With a stylishly thin panel profile (only 6.5mm at its thinnest) and a compact base that's approximately 29% smaller than its predecessor¹, you can free up valuable desk space.

Adjust to your comfort: Pivot, tilt, swivel and adjust the height of your monitor for a comfortable setup all day long. Our improved design, with the hinge on the riser, makes adjustments easier.

Clean and clutter-free: Focus on your work while hiding away cable clutter with an improved cable management design.

Easy on the eyes: This TÜV² Certified monitor has a flicker-free screen with ComfortView, a feature that reduces harmful blue light emissions. It's designed to optimize eye comfort even over an extended period of time.



MAXIMIZE PRODUCTIVITY

Expand your efficiency: The virtually borderless design featuring InfinityEdge lets you enjoy a nearly seamless view of your content across multiple monitors. And, with a Dell dual monitor set up, you can increase your productivity by up to 21%³.

More ways to multitask: Easily organize multiple applications using predefined templates or a customized template with the Easy Arrange feature on Dell Display Manager software. Plus, you can conveniently tile your applications across a multi-monitor setup.

Get right to work: With Auto-restore on Dell Display Manager, you can disconnect, reconnect and all of your applications will be in the same position where you left off.

THANK YOU
FOR MAKING
DELL MONITORS
#1 WORLDWIDE*

Peace of mind: Dell Premium Panel Exchange allows a free panel replacement during the Limited Hardware Warranty⁴ period even if only one bright pixel is found.

Minimize downtime: Your monitor comes with a 3-year Advanced Exchange Service⁵ so that if a replacement becomes necessary, it will be shipped to you the next business day during your 3-year Limited Hardware Warranty.⁴

Get a higher level of support: Upgrade to 24x7, in-region technical phone support from qualified engineers with Dell ProSupport option.⁶

Features & Technical Specifications

Monitor

Diagonal Viewing Size	Dell UltraSharp 27 Monitor – U2719D 68.47 cm (27 inches)
Active Display Area	
Height	335.66 mm (13.21")
Width	596.74 mm (23.49")
Maximum Preset Resolution	2560 x 1440 @ 60 Hz
Aspect Ratio	16:9
Pixel Pitch	0.233 mm x 0.233 mm
Pixel Per Inch (PPI)	109
Brightness	350 cd/m ² (typical)
Color Support	Color Gamut ⁷ (typical): 99% sRGB, 99% REC709, 85% DCI-P3 Color Depth: 16.7 million colors
Color Calibration Accuracy	Delta E < 2 (average)
Contrast Ratio	1000: 1 (typical)
Viewing Angle	178°/178°
Response Time	8 ms (Normal); 5 ms (Fast)
Panel Type	In-Plane Switching Technology
Backlight Technology	LED
ComfortView with Flicker-free screen	Yes
Dell Display Manager Compatibility	Yes, Easy Arrange and other key features
Remote Asset Management	Yes, via Dell Command Monitor
Display Screen Coating	Anti-glare treatment of the front polarizer (3H) hard coating

Connectivity

Connectors	1 x DP 1.4 (HDCP 1.4), 1 x DP (out) with MST (HDCP 1.4), 1 x HDMI 1.4 (HDCP 1.4), 2 x USB 3.0 downstream port, 2 x USB 3.0 with BC1.2 charging capability at 2A (max), 1 x USB 3.0 upstream port, 1 x Analog 2.0 audio line out (3.5 mm jack)
------------	---

Design Features

Adjustability	Height-adjustable stand (130 mm), Tilt (-5° to 21°) Swivel (-40° to 40°), Pivot (Yes) Clockwise and Counterclockwise
Security	Security lock slot (cable lock sold separately), Anti-theft stand lock slot (to panel)
VESA mounting support (wall mount sold separately)	VESA mounting holes (100 mm x 100 mm - behind attached VESA cover)

Power

AC input voltage/frequency/current	100 VAC to 240 VAC / 50 Hz or 60 Hz ± 3 Hz / 1.6 A (maximum)
Power Consumption (Operational)	30 W (typical), 74 W (maximum) ⁸
Power Consumption Stand by / Sleep	Less than 0.3W

Dimensions (with stand)

Height (Compressed ~ Extended)	390.2 mm ~ 520.2 mm (15.36" ~ 20.48")
Width	612.2 mm (24.10")
Depth	180.0 mm (7.09")

Weight

Weight (panel only - for VESA mount)	3.92 kg (8.64 lb)
Weight (with stand)	5.96 kg (13.14 lb)
Shipping Weight	8.52 kg (18.78 lb)

Standard Service Plan

Premium Panel Exchange, 3 Years Advanced Exchange Service⁵ & Limited Hardware Warranty⁴

Optional Service Plan

Dell ProSupport⁷

Environmental Compliance

ENERGY STAR®, EPEAT® Gold registered where applicable⁹, RoHS Compliant, TCO-Certified Display, BFR/PVC free monitor (excluding external cables), meets NFPA 99 leakage current requirements, Arsenic-Free glass and Mercury-Free for the panel only

What's in the box?

Components

- Monitor with stand

Cables

- DisplayPort cable (DP to DP)
- USB 3.0 upstream cable
- Power cable

Documentation

- Quick Setup Guide
- Factory Calibration Report
- Safety and regulatory information


Adjustability and connectivity

DELL ULTRASHARP 27 MONITOR | U2719D


Easily adjust the panel to your preferred viewing position.



Back view -
Cable management slot

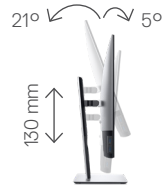

Tilt and height adjustable

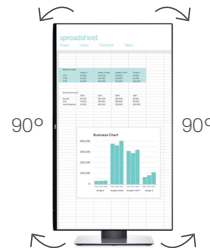


Pivot



Swivel

Connectivity

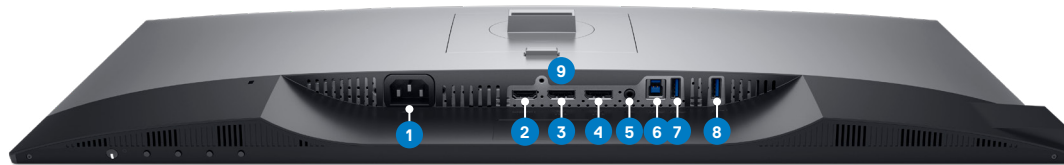

- | | | |
|----------------------|-------------------------------------|---|
| 1 AC power connector | 4 DP connector (Out) | 7 USB downstream port |
| 2 HDMI connector | 5 Audio line-out port ¹⁰ | 8 USB downstream port (with power charging) |
| 3 DP connector (In) | 6 USB upstream port | 9 Stand lock |



RECOMMENDED ACCESSORIES



DELL DUAL MONITOR
STAND | MDS19

Enjoy toolless monitor installation with Quick Release and the flexibility to pivot, tilt, swivel and adjust the height of each monitor independently. Features a small footprint and neat cable management.



DELL PRO STEREO
SOUNDBAR | AE515M

Optimize conference calls and multimedia streaming with exceptional audio clarity. Minimize background noise with the dual mic array and echo-cancelling feature.



DELL PREMIER WIRELESS
KEYBOARD AND MOUSE | KM717

Enjoy an elegant design that fits into virtually any workspace. Connect up to six compatible devices using 2.4 GHz wireless through Dell Universal Pairing or via Bluetooth 4.0.

* Dell monitors are #1 Worldwide for 7 consecutive years (2013, Q2 to 2020, Q2)! Source: IDC Worldwide Quarterly PC Monitor Tracker, Q2, 2020.

1 Based on Dell internal analysis comparing the area of the monitor base of Dell U2719D vs U2717D.

2 TÜV Certified (ID0000051369 - Flicker Free / ID0000051370 - Low Blue Light Content). For more details, visit www.tuv.com

3 Source: Based on Principled Technologies Report commissioned by Dell, "Improve productivity with the new Dell P Series monitors in a dual-display configuration", November 2018, comparing Dell 24 USB-C Monitor - P2419H/HC and Dell 24 Monitor - P2414H/HC. Actual results will vary. Full report: https://www.principledtechnologies.com/Dell/P2419H_monitor_productivity_1118.pdf

4 For a copy of the Limited Hardware Warranty, write to Dell USA LP, Attn: Warranties, One Dell Way, Round Rock, TX 78682 or see dell.com/warranty.

5 Advanced Exchange: Dell will send you a replacement monitor the next business day in most cases, if deemed necessary after phone/online diagnosis. Shipping times may vary by location and for monitors 55" and above. Fee charged for failure to return defective unit. See dell.com/servicecontracts/global.

6 Availability varies, please visit www.dell.com/support for details.

7 At panel native only, under Custom Mode preset.

8 Maximum power consumption with max luminance and contrast.

9 EPEAT registered where applicable. EPEAT registration varies by country. See www.epeat.net for registration status by country.

10 The audio line-out port does not support headphones.

Dell.com/monitors Product availability varies by country. Please contact your Dell representative for more information.

© 2020 Dell All rights reserved.

Trademarks or trade names may be used in this document to refer to either the entities claiming the marks and names of their products. Dell disclaims proprietary interest in the marks and names of others. Reproduction in any manner whatsoever without express written permission from Dell is strictly forbidden.

