



Product Compliance

For compliance documentation, visit the product page on TE.com>


|                                               |                                                                                                                               |
|-----------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------|
| EU RoHS Directive 2011/65/EU                  | Compliant                                                                                                                     |
| EU ELV Directive 2000/53/EC                   | Compliant                                                                                                                     |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold                                                                                       |
| EU REACH Regulation (EC) No. 1907/2006        | Current ECHA Candidate List: JAN 2025 (247)<br>Candidate List Declared Against: JAN 2025 (247)<br>Does not contain REACH SVHC |
| Halogen Content                               | Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free                                           |
| Solder Process Capability                     | Not applicable for solder process capability                                                                                  |

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts




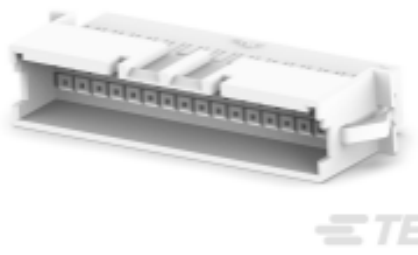


TE Part # 3-2324584-4  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

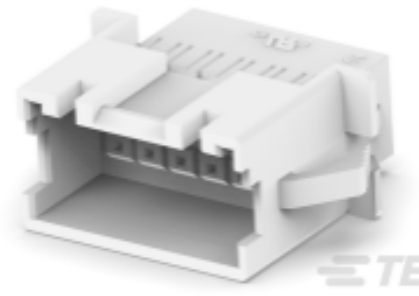


TE Part # 1-2324584-2  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

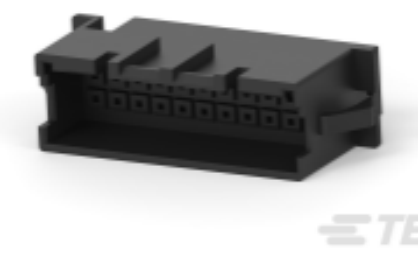


TE Part # 2-2324584-2  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

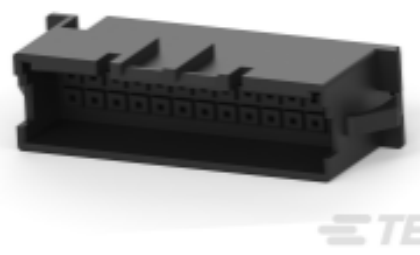


TE Part # 2-2324584-6  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

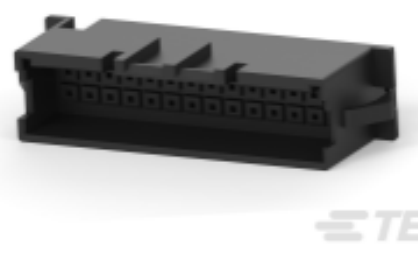


TE Part # 2-2324584-8  
HSG,REC,PANEL MOUNT,DUAL ROW,EP2.5

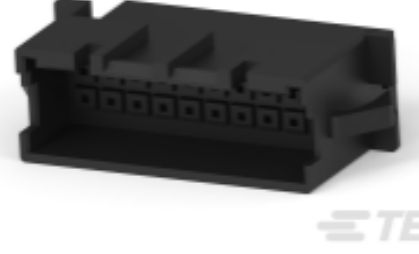


TE Part # 2-2324584-0  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

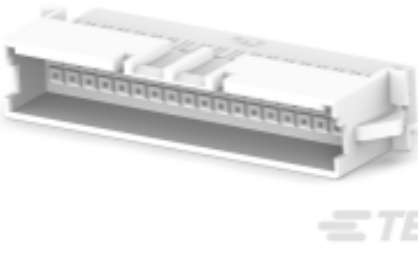


TE Part # 3-2324584-8  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

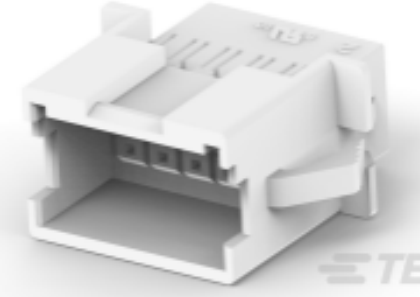


TE Part # 1-2323745-0  
HSG,REC,PANEL MOUNT,GWT,DUALROW,EP2.5

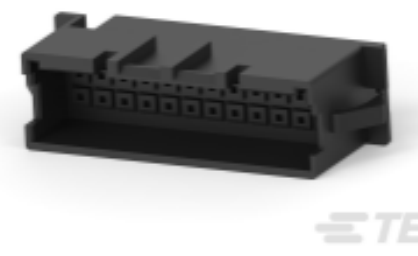


TE Part # 2-2324584-4  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

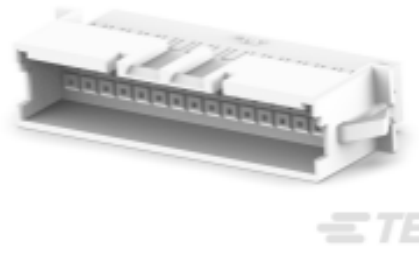

TE Part # 3-2324584-2  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

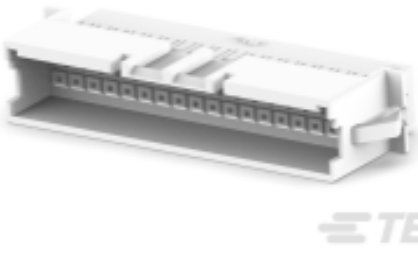

TE Part # 3-2324584-6  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

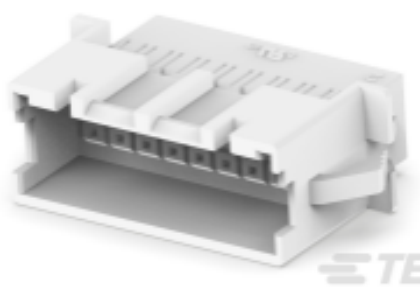


TE Part # 1-2324584-8  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5




TE Part # 1-1969540-0  
HOUSING, PLUG, 10P,DUAL ROW,EP2.5




TE Part # 1969594-8  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

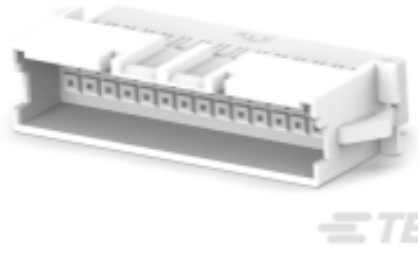

TE Part # 3-2324584-0  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

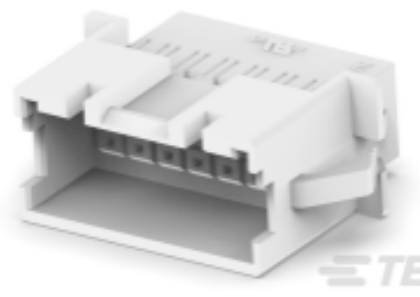

TE Part # 1-2324584-4  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

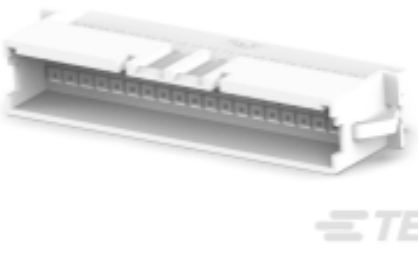

TE Part # 4-2324584-0  
HSG,REC,PANEL MOUNT,DUALROW,EP2.5

Customers Also Bought





TE Part #160927-4  
FF 250 REC 1.0-2.5MM2 TPPB



TE Part #1903120-1  
DYNAMIC D1000 TAB CONT TIN (M) REEL



TE Part #52949-1  
PG SPR SPD 22-16COMM 22-18MIL6



TE Part #53247-2  
TERMINAL,PG SPR SPD 12-10 8



TE Part #2-34149-1  
PG R 22-16 COMM 22-18 MIL 10



TE Part #206247P038  
SCT-NO.4-E2-0-STK



TE Part #52041-3  
TERMINAL,R PG 8 1/4



TE Part #2-34152-2  
PG R 22-16 COMM 22-18 MIL 3/8



TE Part #52955-1  
TERMINAL,PG SPR SPD 16-14 6



TE Part #2-34806-2  
PIDG 16-14HD R 1/4; TAPE

Documents

Product Drawings

HSG,REC,PANEL MOUNT,DUALROW,EP2.5

English

CAD Files

3D PDF

3D

Customer View Model

ENG\_CVM\_CVM\_1-1969594-0\_A.2d\_dxf.zip

English

Customer View Model

ENG\_CVM\_CVM\_1-1969594-0\_A.3d\_igs.zip

English

Customer View Model

ENG\_CVM\_CVM\_1-1969594-0\_A.3d\_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages



7-1773461-6\_EP2.5\_Connector\_Series

English

Product Specifications

Application Specification

English

Instruction Sheets

Instruction Sheet (U.S.)

English

Agency Approvals

VDE Certificate

English