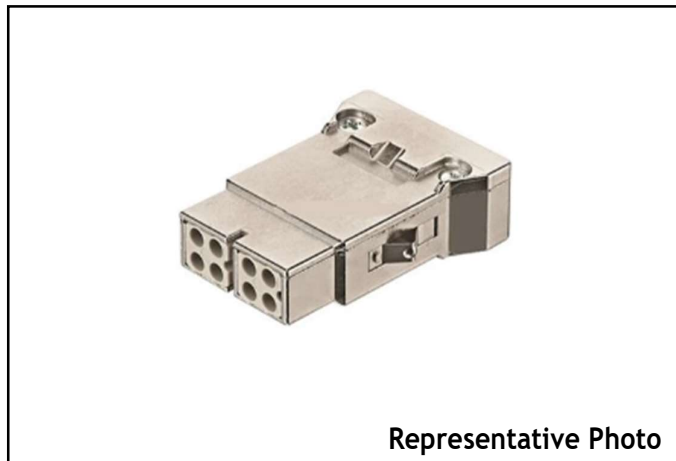


Features

- RS PRO megabit module.

RS PRO Industrial Power Connectors

RS Stock No.: 0457218, 0457219,
0457220



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price

Product Description

- Inserts have a grounded contact to stop incorrect polarisation and contacts are mounted in the insert. This also means no additional tooling is required. The Inserts are available in the most popular sizes 6 PE, 10 PE, 16 PE, 24 PE, 32 PE and 48 PE.*

General Specifications

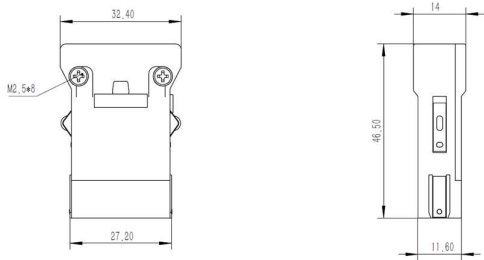
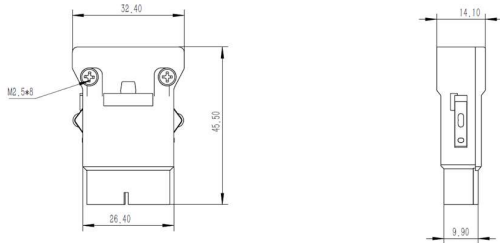
Flammability acc. to UL 94	V 0
Limiting temperature	-40 ... +85 °C
Mating cycles	□500
Material (insert)	Polycarbonate
Material (outer conductor)	zinc alloy

Mechanical Specifications

Contacts	2x4+shielding
Cable Entry	Back
No. of contact	2
acc. to EN 61984	10 A 50 V 0.8 kV 3
Surface	Passivated
Clamping range	5-12mm

Electrical Specifications

Insulation resistance	□4 mΩ
-----------------------	-------

RS Pro MegaBit Module 10 A 50 V 0.8 kV 3	
Male insert (M) Part Number: 0457218	
	
Female insert (F) Part Number: 0457219	
	
RS Pro Adapter Module	
Male insert (M) Part Number: 0457220	
	