



Dimensions – Diam. arbre 20-65 mm

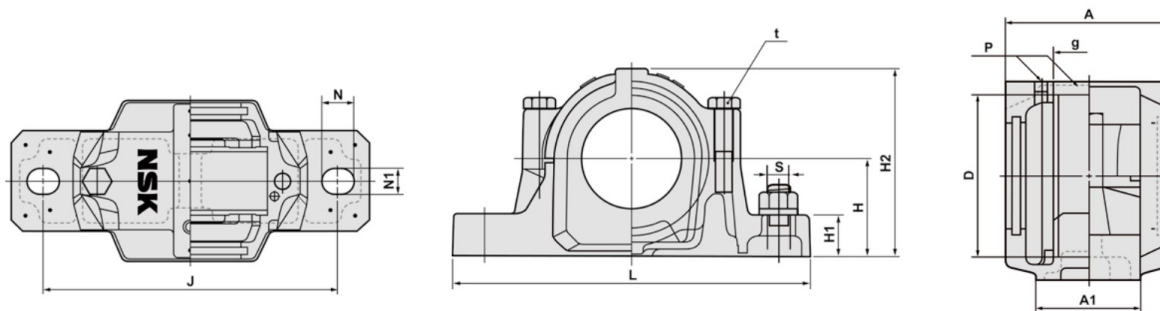

Diam. arbre D (mm)	Roulement		Manchon de serrage	Kit de bagues d'arrêt (2 bagues)	Corps de palier	Désignation du corps de palier	D (mm)	H (mm)	J (mm)	A (mm)	L (mm)	A1 (mm)	H1 (mm)	H2 (mm)	
	à billes	à rouleaux													
20	1205K	-	H205	SR52x5	SNN505	SNN505	52	40	130	70	165	46	22	73	
	2205K	22205K	H305	SR52x3.5											
	1305K	21305K	H305	SR62x7.5	SNN605										
	2305K	-	H2305	SR62x4		SNN506-605	62	50	150	80	185	52	22	88	
25	1206K	-	H206	SR62x8	SNN506										
	2206K	22206K	H306	SR62x6											
	1306K	21306K	H306	SR72x7.5	SNN606										
	2306K	-	H2306	SR72x3.5		SNN507-606	72	50	150	85	185	52	22	93	
30	1207K	-	H207	SR72x8.5	SNN507										
	2207K	22207K	H307	SR72x5.5											
	1307K	21307K	H307	SR80x9	SNN607										
	2307K	-	H2307	SR80x4		SNN508-607	80	60	170	90	205	60	25	107	
35	1208K	-	H208	SR80x10.5	SNN508										
	2208K	22208K	H308	SR80x8											
	1308K	21308K	H308	SR90x9	SNN608	SNN510-608	90	60	170	95	205	60	25	113	
	2308K	22308K	H2308	SR90x4											
40	1209K	-	H209	SR85x5.5	SNN509	SNN509	85	60	170	90	205	60	25	111	
	2209K	22209K	H309	SR85x3.5											
	1309K	21309K	H309	SR100x9.5	SNN609	SNN511-609	100	70	210	100	255	70	28	129	
	2309K	22309K	H2309	SR100x4											
45	1210K	-	H210	SR90x10.5	SNN510	SNN510-608	90	60	170	95	205	60	25	113	
	2210K	22210K	H310	SR90x9											
	1310K	21310K	H310	SR110x10.5	SNN610	SNN512-610	110	70	210	110	255	70	30	134	
	2310K	22310K	H2310	SR110x4											
50	1211K	-	H211	SR100x11.5	SNN511	SNN511-609	100	70	210	100	255	70	28	129	
	2211K	22211K	H311	SR100x9.5											
	1311K	21311K	H311	SR120x11	SNN611	SNN513-611	120	80	230	115	275	80	30	150	
	2311K	22311K	H2311	SR120x4											
55	1212K	-	H212	SR110x13	SNN512	SNN512-610	110	70	210	110	255	70	30	134	
	2212K	22212K	H312	SR110x10											
	1312K	21312K	H312	SR130x12.5	SNN612	SNN515-612	130	80	230	120	280	80	30	155	
	2312K	22312K	H2312	SR130x5											
60	1213K	-	H213	SR120x14	SNN513	SNN513-611	120	80	230	115	275	80	30	150	
	2213K	22213K	H313	SR120x10											
	1313K	21313K	H313	SR140x12.5	SNN613	SNN516-613	140	95	260	130	315	90	32	175	
	2313K	22313K	H2313	SR140x5											
65	1215K	-	H215	SR130x15.5	SNN515	SNN515-612	130	80	230	120	280	80	30	155	
	2215K	22215K	H315	SR130x12.5											
	1315K	21315K	H315	SR160x14	SNN615	SNN518-615	160	100	290	145	345	100	35	193	
	2315K	22315K	H2315	SR160x5											

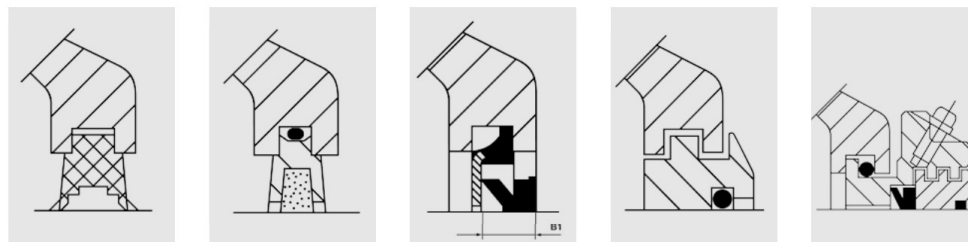

Joints de type G

Joints de type C

Joints de type V

Joints de type TS-U

Joints de type TACK

	g (mm)	t (mm)	N (mm)	N1 (mm)	s (mm)	P	KIT joints de type G	KIT joints de type C	KIT joints de type V	Joints de type TS-U	Joints de type TACK	Obturbateur	Masse (kg)
	25	M10	20	15	M12	R1/8	G505-KIT	C505-KIT	V505-KIT (6 ±0.8)	TS505U	TACK505	505A 505A	1.45
	32	M10	20	15	M12	R1/8	G605-KIT	C605-KIT	V605-KIT (6 ±0.8)	TS605U	TACK605	505A 506A 506A	2.00
							G506-KIT	C506-KIT	V506-KIT (6 ±0.8)	TS506U	TACK506	506A 506A	
	34	M10	20	15	M12	R1/8	G606-KIT	C606-KIT	V606-KIT (6 ±0.8)	TS606U	TACK606	507A 507A	2.20
							G507-KIT	C507-KIT	V507-KIT (6 ±0.8)	TS507U	TACK507	507A 507A	
	39	M10	20	15	M12	R1/8	G607-KIT	C607-KIT	V607-KIT (6 ±0.8)	TS607U	TACK607	508A 508A	2.90
							G508-KIT	C508-KIT	V508-KIT (6 ±0.8)	TS508U	TACK508	508A 508A	
	41	M10	20	15	M12	R1/8	G608-KIT	C608-KIT	V608-KIT (6 ±0.8)	TS608U	TACK608	510A 510A	3.10
	30	M10	20	15	M12	R1/8	G509-KIT	C509-KIT	V509-KIT (7 ±1)	TS509U	TACK509	509A 509A	3.00
	44	M12	24	18	M16	R1/8	G609-KIT	C609-KIT	V609-KIT (7 ±1)	TS609U	TACK609	511A 511A	4.80
	41	M10	20	15	M12	R1/8	G510-KIT	C510-KIT	V510-KIT (7 ±1)	TS510U	TACK510	510A 510A	3.10
	48	M12	24	18	M16	R1/8	G610-KIT	C610-KIT	V610-KIT (7 ±1)	TS610U	TACK610	512A 512A	5.40
	44	M12	24	18	M16	R1/8	G511-KIT	C511-KIT	V511-KIT (7 ±1)	TS511U	TACK511	511A 511A	4.80
	51	M12	24	18	M16	R1/8	G611-KIT	C611-KIT	V611-KIT (7 ±1)	TS611U	TACK611	513A 513A	6.60
	48	M12	24	18	M16	R1/8	G512-KIT	C512-KIT	V512-KIT (7 ±1)	TS512U	TACK512	512A 512A	5.40
	56	M12	24	18	M16	R1/8	G612-KIT	C612-KIT	V612-KIT (7 ±1)	TS612U	TACK612	515A 515A	6.80
	51	M12	24	18	M16	R1/8	G513-KIT	C513-KIT	V513-KIT (7 ±1)	TS513U	TACK513	513A 513A	6.60
	58	M16	28	22	M20	R1/4	G613-KIT	C613-KIT	V613-KIT (7 ±1)	TS613U	TACK613	516A 516A	10.20
	56	M12	24	18	M16	R1/8	G515-KIT	C515-KIT	V515-KIT (7 ±1)	TS515U	TACK515	515A 515A	6.80
	65	M16	28	22	M20	R1/4	G615-KIT	C615-KIT	V615-KIT (7 ±1)	TS615U	TACK615	518A 518A	13.00