


Geberit Mapress Carbon Steel adaptor with female thread and plain end

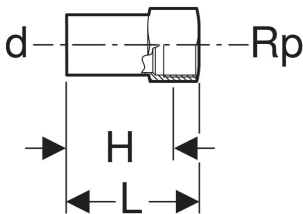

Example image

CHARACTERISTICS

- Outside zinc-plated

TECHNICAL DATA

Product material Non-alloy steel 1.0034 E195 (EN 10305)

Art. no.	DN	d, ø mm	Rp "	L cm	H cm
These articles are suitable for the following system: Geberit Mapress Carbon Steel					
21907	10	12	3/8	5.4	4.4
21901	10 / 15	12	1/2	5.8	4.5
21908	12 / 10	15	3/8	7.4	6
21902	12 / 15	15	1/2	6.1	4.8
21903	15	18	1/2	6.1	4.8

Art. no.	DN	d, ø mm	Rp "	L cm	H cm
21904	15 / 20	18	3/4	6.4	4.9
21905	20 / 15	22	1/2	6.2	4.9
21906	20	22	3/4	6.5	5
21910	25 / 15	28	1/2	7.1	5.6
21912	32 / 15	35	1/2	7.7	5.2
21914	40 / 15	42	1/2	8.1	5.7
21916	50 / 15	54	1/2	8.6	6.2
21918	65 / 15	76.1	1/2	10.5	8.7
21920	80 / 15	88.9	1/2	11.5	10.2
21922	100 / 15	108	1/2	12.7	11.4

These articles are suitable for the following system: **Geberit Mapress Carbon Steel (FKM blue)**

21907	10	12	3/8	5.4	4.4
21901	10 / 15	12	1/2	5.8	4.5

Art. no.	DN	d, ø mm	Rp "	L cm	H cm
21908	12 / 10	15	3/8	7.4	6
21902	12 / 15	15	1/2	6.1	4.8
21903	15	18	1/2	6.1	4.8
21904	15 / 20	18	3/4	6.4	4.9
21905	20 / 15	22	1/2	6.2	4.9
21906	20	22	3/4	6.5	5
21910	25 / 15	28	1/2	7.1	5.6
21912	32 / 15	35	1/2	7.7	5.2
21914	40 / 15	42	1/2	8.1	5.7
21916	50 / 15	54	1/2	8.6	6.2
21918	65 / 15	76.1	1/2	10.5	8.7
21920	80 / 15	88.9	1/2	11.5	10.2
21922	100 / 15	108	1/2	12.7	11.4