

connecting comb for connecting identical potentials, current-carrying capacity for infeed max. 10 A, 4-pole



product brand name		SIRIUS	
product designation		Connecting comb	
design of the product		current-carrying capacity for infeed max. 10 A, 4-pole	
product type designation		3RQ4	
General technical data			
flammability class of enclosure material		UL94 V-0	
reference code according to IEC 81346-2		X	
Substance Prohibittance (Date)		09/26/2024	
Weight		0.7 g	
Installation/ mounting/ dimensions			
height		24.2 mm	
width		20.2 mm	
depth		3.6 mm	
Ambient conditions			
relative humidity during operation		10 ... 95 %	
Approvals Certificates			
General Product Approval		other	Environment




[Confirmation](#)



Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
Information- and Downloadcenter (Catalogs, Brochures,...)
<https://www.siemens.com/ic10>
Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=3RQ4901-0B>
Cax online generator
<http://support.automation.siemens.com/WW/CAXorder/default.aspx?lang=en&mlfb=3RQ4901-0B>
Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/3RQ4901-0B>
Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, EPLAN macros, ...)
http://www.automation.siemens.com/bilddb/cax_de.aspx?mlfb=3RQ4901-0B&lang=en
Characteristic: Derating
<https://support.industry.siemens.com/cs/ww/en/ps/3RQ4901-0B/manual>

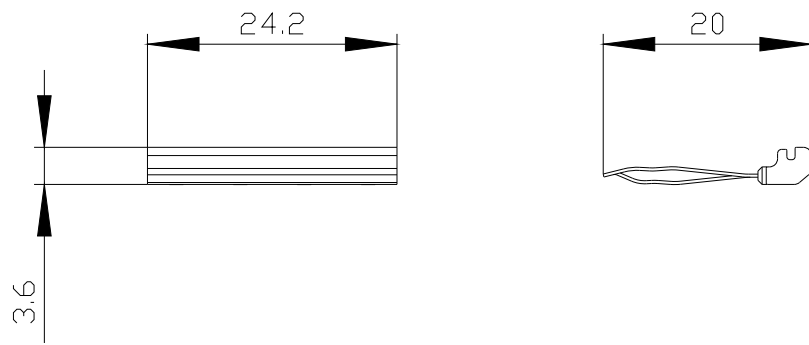

last modified:

4/3/2025 