



Accessories for *BENNING* testers and measuring instruments safe – functional – indispensable



Case for testers and measuring instruments item no. 711019

High-quality cases for testers and measuring instruments for professional storage of all testers and measuring instruments, made of polyester fabric with carrying handle and detachable shoulder strap

Tester case

item no. 010910

Practical carrying case made of leather cloth with zipper, suitable for all *DUSPOL*® voltage testers, *PROFIPOL*®, *DU-TEST*® and *TRITEST*® control testers



BENNING TA 1

item no. 044124

Ø 4 mm safety crocodile clips, two pieces, red/black, professional equipment, CAT III 1000 V



BENNING TA 2

item no. 044125

set of Ø 4 mm safety measuring leads, six pieces, red/black, professional equipment, consisting of:

- safety measuring leads (silicone), CAT III 1000 V
- safety test probes (4 mm measuring tip), CAT II 1000 V
- safety crocodile clips, CAT III 1000 V



BENNING TA 3

item no. 044126

set of Ø 4 mm safety measuring leads, eight pieces, red/black, professional equipment, CAT III 1000 V, consisting of:

- safety measuring leads (silicone)
- safety test probes (slender measuring tip)
- safety claw clamps
- safety crocodile clips



BENNING TA 4

item no. 044120

magnetic holder for Multimeter and BENNING IT 101, 3 pieces, consisting of:


- magnetic holder
- adapter and belt, for attachment of BENNING Multimeters to switching cabinets, machine and system parts



Ø 4 mm safety measuring leads with 2 mm measuring tip

item no. 044146

Ø 4 mm safety measuring leads 2 pieces, red/black, L = 1.40 m, with 2 mm measuring tip CAT IV 600 V/ CAT III 1000 V (with protective caps), CAT II 1000 V (without protective caps)

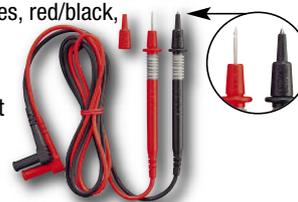

Ø 4 mm safety measuring leads with 4 mm measuring tip

item no. 044145

Ø 4 mm safety measuring leads 2 pieces, red/black, L = 1.40 m, with 4 mm measuring tip CAT IV 600 V/ CAT III 1000 V (with protective caps), CAT II 1000 V (without protective caps)



Set of safety measuring leads for *BENNING MM 4*

item no. 044119

set of Ø 4 mm safety measuring leads, 4 pieces, consisting of:

- safety measuring leads with 2 mm measuring tip
- 2 measuring probes with 2 mm measuring tip



Temperature probe (type K)

item no. 044121

insertion probe (V4A steel tube) for flexible substances, liquids, gases and air, measuring range:

-196 °C to +800 °C, suitable for *BENNING MM 1-3*, *MM 7-1*, *MM 11* and *CM 8* digital measuring instruments

