



Product Compliance


For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant with Exemptions
EU ELV Directive 2000/53/EC	Compliant with Exemptions
China RoHS 2 Directive MIIT Order No 32, 2016	Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2024 (240) Does not contain REACH SVHC
Halogen Content	BFR/CFR/PVC Free, but Br/Cl >900 ppm in other sources.
Solder Process Capability	Reflow solder capable to 245°C


Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Customers Also Bought

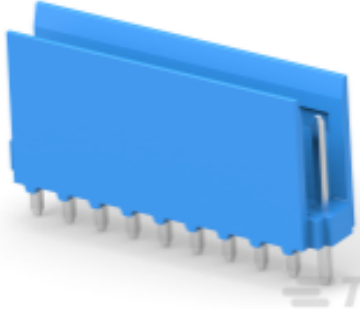

TE Part #CAT-AM74-H3401
HE13/HE14 TH Headers, SRST

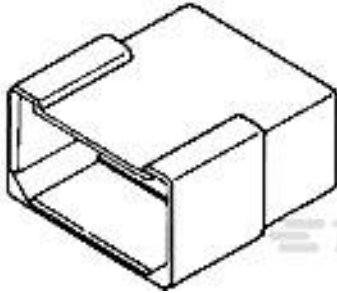


TE Part #180906
FF 250 TAB HSG 6P NYLON NAT

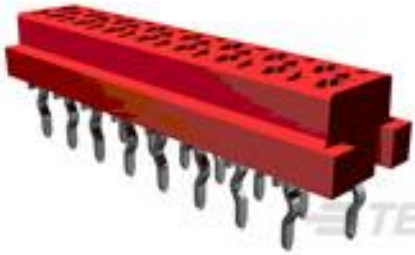

TE Part #8-215079-6
MICRO-MATCH FOB.16P



TE Part #878498-000
202K163-25-0

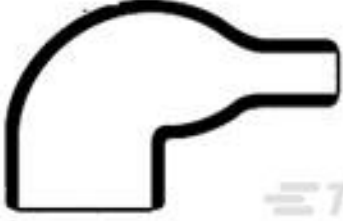

TE Part #814554-000
222A121-25-0



TE Part #1676183-2
RN 0805 13K 0.1% 10PPM 1KRL



TE Part #1676419-2
RN 0805 6K98 0.1% 10PPM 1KRL



TE Part #1-1337582-0
MCX SMT Skt 50Ohm Gold Pltd

Documents

CAD Files

Customer View Model

ENG_CVM_CVM_1623916-2_BA.2d_dxf.zip

English

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1623916-2_BA.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1623916-2_BA.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

1309350_PASSIVE_COMPONENT

English

SMD Trimmers - Type 3203 Series - Tyco Electronics Passives

English