


# E40502



## Process adapters pipe fitting DIN11851

ADAPT DIN11851 DN40

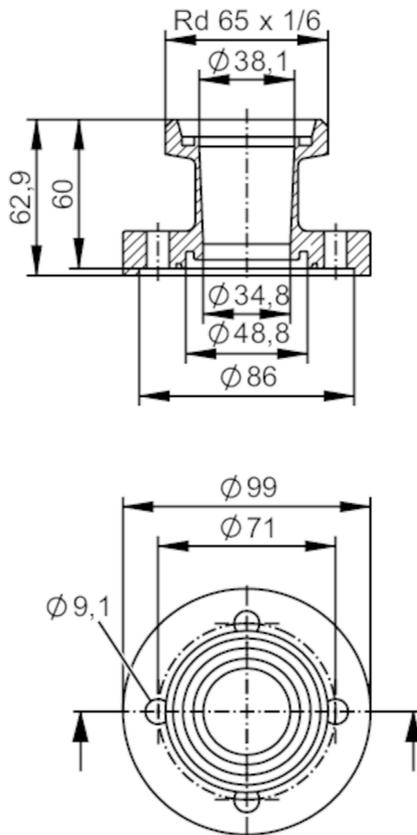

EC 1935/2004 FCM FDA

Application	
Design	for volumetric flow meters SMF
Application	food and beverage industry; hygienic systems
Pressure rating	40 bar 4 MPa
Tests / approvals	
Pressure Equipment Directive	A possible classification to PED depends on the application and has to be carried out by the user / operator.
Safety instructions	The compatibility between medium and product material has to be checked in all applications.
Mechanical data	
Weight [g]	2620
Materials	stainless steel (316L/1.4404)
Nominal diameter	DN40 (1 1/2")
Sensor connection	ifm-specific device flange
Process connection	hygienic pipe fitting DIN 11851
Process connection suitable for pipe standard	(DIN EN 10357 series A); (DIN 11866 series A); (DIN 11850 series 1); (DIN 11850 series 2)
Surface characteristics Ra/Rz of the wetted parts	Ra ≤ 0.4 µm

# E40502



## Process adapters pipe fitting DIN11851

ADAPT DIN11851 DN40

Accessories	
Items supplied	screws 8
Remarks	
Pack quantity	2 pcs.