


554283 ADNGF-80-50-P-A Compact cylinder - Series from 03-2023

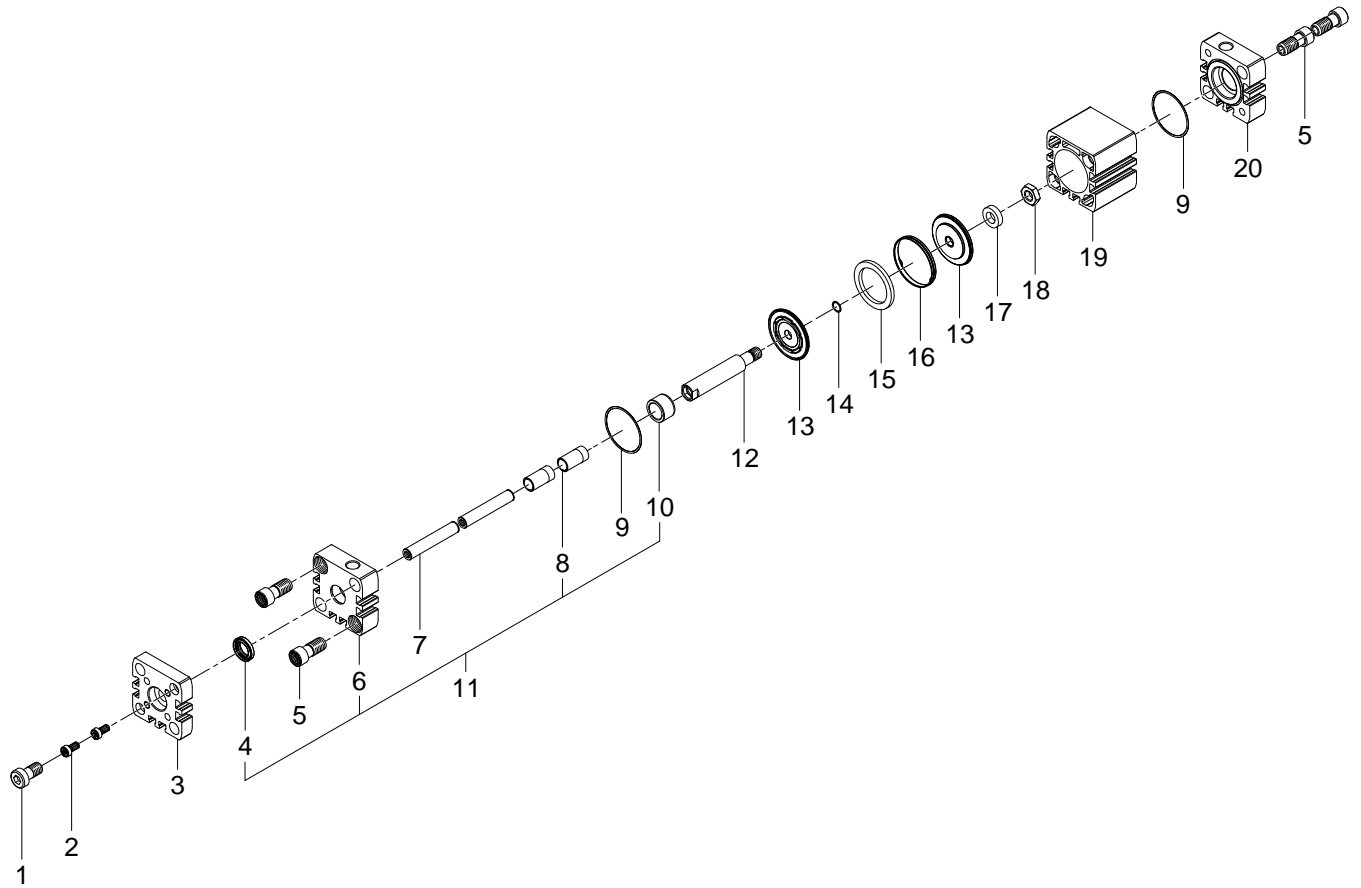

554283 ADNGF-80-50-P-A Compact cylinder - Series from 03-2023

Pos.	Part no.	Type	Note	Qty.	Unit
A	673627	ADN-80-P-A Set of wearing parts	Spare parts: 4, 9, 13, 14, 16	1	PC
1	223363	DIN 6912-M12X25-8.8 Socket head screw	Tightening torque 39 Nm / 28.8 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	1	PC
2	207729	DIN 7984-M5X10-8.8 Socket head screw	Tightening torque 4.6 Nm / 3.4 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	2	PC
3	8155055	ADNGF-80 Moment compensator		1	PC
4	359748	WIFC1-20X25X4,6-TPE-U Wiper seal	Lubricate with 684474 LUB-KC1 during assembly	1	PC
5	200688	ISO 4762-M6X20-10.9 Socket head screw	Tightening torque 8 Nm / 5.9 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	8	PC
6		ADNGF-80:CO Bearing cap	Not available separately, see position 11	1	PC
7	8155096	ADNGF-80/100-X- Guide rod		2	PC
8		PSM-1214-15 Plain bearing	Not available separately, see position 11	2	PC
9		B-80X1,5-N-NBR70 O-ring ISO3601	Lubricate with 684474 LUB-KC1 during assembly Not available separately, see position A	2	PC
10		ADN-80/100 Bearing	Not available separately, see position 11	1	PC
11		ADNGF-80 Bearing cap module	Not available	1	PC
12	683599	ADN-80- - Piston rod	When ordering please specify the configuration (see type plate)	1	PC
13		BA-K01D-080 Piston module	Not available separately, see position A	2	PC
14		B-14X1,5-N-NBR75 O-ring ISO3601	Not available separately, see position A	1	PC
15	4760182	76,9X58X6BA-K01M-080 Ring magnet		1	PC
16		BA-K01F-080 Guiding band	Not available separately, see position A	1	PC
17	668949	DIN 7349-15 Disc		1	PC
18	204153	DIN 439-B-M14X1,5-04 Hex nut	Tightening torque 46 Nm / 33.9 lbf ft Use locking compound 8181258 CYBERBOND TI 7680	1	PC
19		ADN-80-X Cylinder barrel	Lubricate with 684474 LUB-KC1 during assembly Not available	1	PC
20	663894	ADN-80 End cap		1	PC