



Product Description

MASTER PL-T 4 Pin

Energy saving compact fluorescent lamp Compact long-arc low-pressure mercury discharge lamp Envelope consists of 6 parallel narrow fluorescent tubes

Benefits

- Optimal light performance for short or long operation per switch on
- More light (about 15% more) per light point than common
- Long life and sustainable light output

Features

- 4-pin base without glow switch starter and capacitor
- Fast light run up under all circumstances
- Philips invented bridge technology applied
- Dimming is possible


Application

- Designed for general or supplementary lighting in professional and semi-professional environments
- Ideal for use in recessed or surface mounted downlighters, wall units, outdoor lighting
- First choice for short switching cycles, emergency lighting and deep dimming


Related products




Dimensional drawing

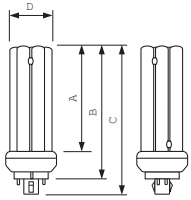


| Product | A (Max) | B (Max) | C (Max) | D (Max) |
|-------------------|---------|---------|---------|---------|
| PL-T 13W/827/4P M | 66.7 | 91.0 | 106.7 | 41.0 |
| PL-T 13W/830/4P M | 66.7 | 91.0 | 106.7 | 41.0 |
| PL-T 13W/840/4P M | 66.7 | 91.0 | 106.7 | 41.0 |

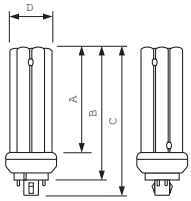


| Product | A (Max) | B (Max) | C (Max) | D (Max) |
|-------------------|---------|---------|---------|---------|
| PL-T 18W/827/4P M | 71.7 | 96.0 | 111.7 | 41.0 |
| PL-T 18W/830/4P M | 71.7 | 96.0 | 111.7 | 41.0 |
| PL-T 18W/840/4P M | 71.7 | 96.0 | 111.7 | 41.0 |

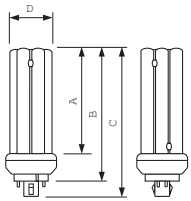

| Product | A (Max) | B (Max) | C (Max) | D (Max) |
|-------------------|---------|---------|---------|---------|
| PL-T 26W/827/4P M | 86.7 | 111.0 | 126.7 | 41.0 |
| PL-T 26W/830/4P M | 86.7 | 111.0 | 126.7 | 41.0 |
| PL-T 26W/840/4P M | 86.7 | 111.0 | 126.7 | 41.0 |
| PL-T 32W/827/4P M | 98.7 | 123.0 | 138.7 | 41.0 |
| PL-T 32W/830/4P M | 98.7 | 123.0 | 138.7 | 41.0 |
| PL-T 32W/840/4P M | 98.7 | 123.0 | 138.7 | 41.0 |

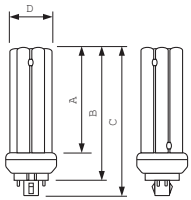

| Product | A (Max) | B (Max) | C (Max) | D (Max) |
|-------------------|---------|---------|---------|---------|
| PL-T 42W/827/4P M | 120.7 | 145.0 | 160.7 | 41.0 |
| PL-T 42W/830/4P M | 120.7 | 145.0 | 160.7 | 41.0 |
| PL-T 42W/840/4P M | 120.7 | 145.0 | 160.7 | 41.0 |

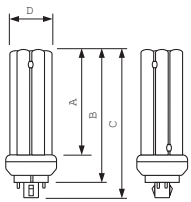

| Product | A (Max) | B (Max) | C (Max) | D (Max) |
|-------------------|---------|---------|---------|---------|
| PL-T 57W/827/4P M | 157.7 | 182.0 | 197.7 | 41.0 |
| PL-T 57W/830/4P M | 157.7 | 182.0 | 197.7 | 41.0 |
| PL-T 57W/840/4P M | 157.7 | 182.0 | 197.7 | 41.0 |

Compare table

| Order code | Full product name | Cap-Base | Color Code | Color Designation (text) | Lamp Wattage | Energy Efficiency Label (EEL) |
|------------|----------------------------|----------|------------|--------------------------|--------------|-------------------------------|
| 559760 70 | MASTER PL-T 13W/827/4P 1CT | GX24q-1 | 827 | Incandescent White | 13 | A |
| 610447 70 | MASTER PL-T 13W/830/4P 1CT | GX24q-1 | 830 | Warm White | 13 | A |
| 610478 70 | MASTER PL-T 13W/840/4P 1CT | GX24q-1 | 840 | Cool White | 13 | A |
| 559821 70 | MASTER PL-T 18W/827/4P 1CT | GX24q-2 | 827 | Incandescent White | 18 | B |
| 610768 70 | MASTER PL-T 18W/830/4P 1CT | GX24q-2 | 830 | Warm White | 18 | B |
| 610997 70 | MASTER PL-T 18W/840/4P 1CT | GX24q-2 | 840 | Cool White | 18 | B |
| 559937 70 | MASTER PL-T 26W/827/4P 1CT | GX24q-3 | 827 | Incandescent White | 26 | B |
| 611208 70 | MASTER PL-T 26W/830/4P 1CT | GX24q-3 | 830 | Warm White | 26 | B |
| 611253 70 | MASTER PL-T 26W/840/4P 1CT | GX24q-3 | 840 | Cool White | 26 | B |
| 559968 70 | MASTER PL-T 32W/827/4P 1CT | GX24q-3 | 827 | Incandescent White | 32 | B |
| 611284 70 | MASTER PL-T 32W/830/4P 1CT | GX24q-3 | 830 | Warm White | 32 | B |
| 611314 70 | MASTER PL-T 32W/840/4P 1CT | GX24q-3 | 840 | Cool White | 32 | B |
| 560025 70 | MASTER PL-T 42W/827/4P 1CT | GX24q-4 | 827 | Incandescent White | 42 | B |
| 611345 70 | MASTER PL-T 42W/830/4P 1CT | GX24q-4 | 830 | Warm White | 42 | B |
| 611376 70 | MASTER PL-T 42W/840/4P 1CT | GX24q-4 | 840 | Cool White | 42 | B |
| 560056 70 | MASTER PL-T 57W/827/4P 1CT | GX24q-5 | 827 | Incandescent White | 57 | B |
| 611406 70 | MASTER PL-T 57W/830/4P 1CT | GX24q-5 | 830 | Warm White | 57 | B |
| 611451 70 | MASTER PL-T 57W/840/4P 1CT | GX24q-5 | 840 | Cool White | 57 | B |



© 2010 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2010, April 16
data subject to change