
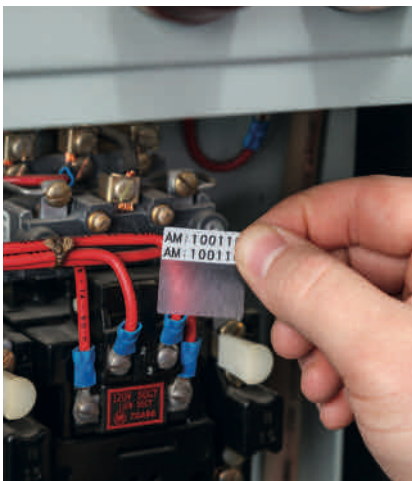
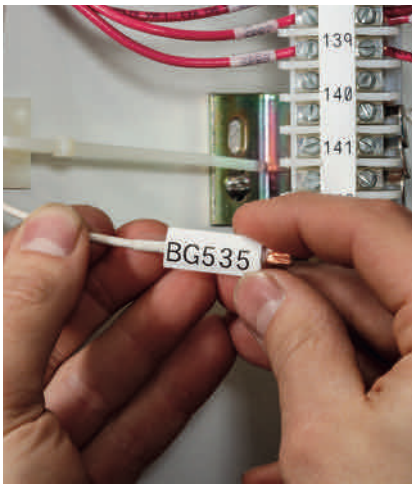


BMP™61 Label Printer

Performance that matches your own

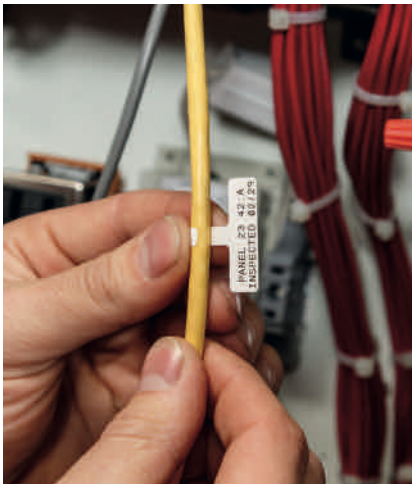

Designed with molded rubber bumpers and a vivid colour touch screen with on screen indicators, the rugged and reliable BMP™ 61 Label Printer will be your trusted identification companion of choice, all day, every day, for years to come.

The BMP™61 Label Printer offers great performance that matches your own. It is portable, fast and can handle a lot of identification challenges thanks to its wireless connectivity and a wide range of durable labels to print on.

Data management versatility

The printer features on-board list management. Use the printer's USB-ports to copy large lists of label design from a computer.

The rugged, portable BMP61 is also available in a wifi-enabled version compatible with the LabelMark label creation software and Brady mobile apps. Simply create or send label designs from a smart phone to the printer for extremely fast and easy label creation on the job.

High Performance

With its 33.8mm/sec print speed, predefined label templates, label creation wizards, built-in label cutter and data serialization options, the BMP61 Label Printer is a durable partner in the field.

Printer

| Article No. | Order Ref. |
|-------------|-------------------|
| 146229 | BMP61 |
| 146226 | BMP61-W |
| 146230 | BMP61-QWERTY-EU |
| 146227 | BMP61-QWERTY-EU-W |
| 148638 | BMP61-AZERTY-EU |
| 146231 | BMP61-AZERTY-EU-W |
| 196453 | BMP61-QWERTY-UK |
| 196454 | BMP61-QWERTY-UK-W |
| 148637 | BMP61-QWERTZ-EU |
| 146224 | BMP61-QWERTZ-EU-W |
| 146223 | BMP61-CYRILLIC |

Kits***

| Article No. | Order Ref. |
|-------------|----------------------|
| 196455 | BMP61-AZERTY-EU-EL* |
| 196456 | BMP61-AZERTY-EU-DA** |
| 196457 | BMP61-QWERTY-EU-EL* |
| 196458 | BMP61-QWERTY-EU-DA** |
| 196461 | BMP61-QWERTZ-EU-EL* |
| 196462 | BMP61-QWERTZ-EU-DA** |
| 196465 | BMP61-CYRILLIC-EL* |
| 196466 | BMP61-CYRILLIC-DA** |

*This Electrical kit ships in a hard case holding a BMP61 Printer, a USB cable, a quick start guide, a battery pack, an AC Adapter, a CD with driver, a product CD, a hand strap, a roll of PTL-19-423, PTL-21-427, PTL-31-499, PSPT-187-1-YL, M61-R-4310, M61-R6010, a LabelMark 6 Standard CD and a BMP61 Magnet.

**This Datacomm kit ships in a hard case holding a BMP61 Printer, a USB cable, a quick start guide, a battery pack, an AC Adapter, a CD with driver, a product CD, a hand strap, a roll of PTL-19-423, PTL-31-427, PTL-8-422, PTL-12-109, M61-R4310, M61-R6010, a LabelMark 6 Standard CD and a BMP61 Magnet.

***Also available with US and UK power charger.

Accessories

| Article No. | Description |
|-------------|----------------------|
| 018556 | Printer cleaning kit |
| 103788 | USB Cable |
| 146221 | Magnet for BMP61 |

| PRINTER | |
|--------------------------|--|
| Includes | This printer ships in a hard case holding a USB cable, a quick start guide, a battery pack, an AC Adapter, a CD with driver, a product CD, a hand strap, a roll of PTL-19-423 and an M61-R6010 ribbon. |
| Weight (kg) | 1.5 |
| Size W x D x L (mm) | 107 x 106 x 328 |
| Keyboard Type | QWERTY, QWERTZ, AZERTY, CYRILLIC |
| Min. Label Width | 5.08 mm |
| Max. Label Width | 50.80 mm |
| Internal Memory Capacity | 512MB of FLASH storage and 512MB of RAM |
| Warranty | 2 years |

| MATERIALS SUPPORTED | |
|---------------------|--|
| Materials Supported | 600+ standard parts: continuous tapes, die cut and bulk label rolls, custom made labels and tapes. |


| FONTS/GRAPHICS/SYMBOLOGIES | |
|----------------------------|-------------------------------------|
| Bar Code Type | Code 39 and 128, other via software |
| Text Sizes (pt) | 4 to 174pt + autosizing |
| Built-in Fonts | Brady Alpine, Brady Fixed Width |

| SOFTWARE & CONNECTIVITY | |
|-------------------------|----------------------------------|
| Connectivity Options | USB 2.0, USB Flash Drive, WIFI |
| Software Compatibility | Labelmark 6.0, Brady Mobile Apps |

| POWER SUPPLY | |
|--------------|---------------------------|
| Battery Type | Rechargeable NiMH Battery |
| Power Supply | AC Power |

| COMPLIANCE | |
|---------------------|------------------------|
| Approval/Compliance | UL; cUL; CE; RoHS; EAC |

i



Consult the video of the BMP61 Label Printer on www.bradyeurope.com/BMP61




WHEN PERFORMANCE MATTERS MOST™

Brady EMEA Locations

| | | | |
|--------------------------|-----------------------|------------------|----------------------|
| Africa | +27 11 704 3295 | Middle East | +971 4881 2524 |
| Benelux | +32 (0) 52 45 78 11 | Norway | +47 70 13 40 00 |
| Central & Eastern Europe | +421 2 3300 4800 | Romania | +40 21 202 3032 |
| Denmark | +4566 14 44 00 | Russia | +7 495 225 93 62 |
| France | +33 (0) 3 20 76 94 48 | Spain & Portugal | +34 900 902 993 |
| Germany | +49 (0) 6103 7598 660 | Sweden | +46 (0) 8 590 057 30 |
| Hungary | +36 23 500 275 | Turkey | +90 212 264 02 20 |
| Italy | +39 02 26 00 00 22 | UK & Ireland | +44 (0) 1295 228 288 |

Prints in 300dpi multiple qualitative high-performance materials

The rugged, thermal transfer BMP61 Label Printer can print on a wide range of durable die-cut, continuous & custom labels including sleeves, self-laminating labels and raised profile labels up to 48,76mm wide.

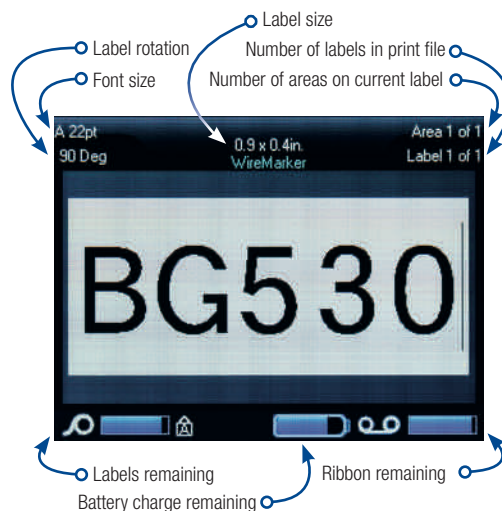

Every BMP61 label and ribbon is automatically recognised and auto-calibrated by the printer. The printer's colour touch screen displays which label material is currently installed and how many labels, how much ink and how much battery is left for maximum ease of use.

Customise your labels in personalised shapes or dimensions, in specific colours or layouts or with your logo already present on the label. Simply insert the custom labels in your BMP61 Label Printer's to solve your identification challenges.



Your Brady Distributor