


Features

- Enhanced, high performance Cat6 cable for LAN applications or future proofing of structured cabling systems
- Conforms to ANSI/TIA-568.2-D & ISO/IEC 11801-1
- HDPE Insulation
- Mylar & AL-Mylar Tape Construction
- UL E164469 Approved Cable
- Backwards Compatible to CAT 3 CAT 5 CAT 5E
- Operation Temp -20c - 60c
- Conductor DC Resistance $\leq 140 \Omega$ /1000m

RS PRO Ethernet Cable

RS Stock No.: 0199207

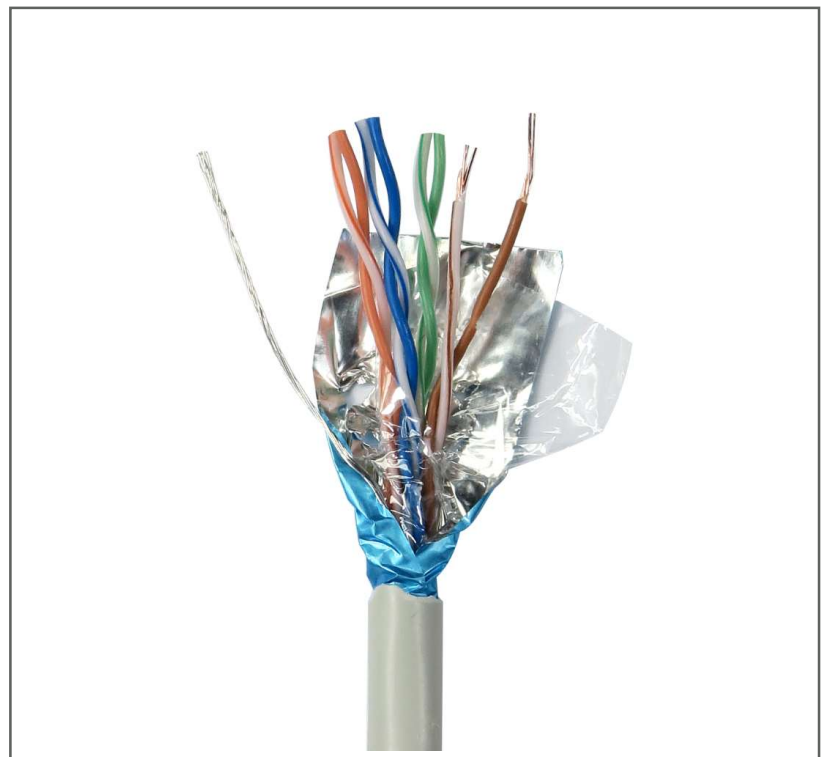

RS PRO is the own brand of RS. The RS PRO Seal of Approval is your assurance of professional quality, a guarantee that every part is rigorously tested, inspected, and audited against demanding standards. Making RS PRO the Smart Choice for our customers.

Product Description

Focused on delivering clear sound with versatile options. The RS Pro Unterminated Cat6 type cables have primary application use for both home and office computer networks. This cable is compliance with CE, UKCA, RoHS, REACH and UL standards. It features an IP67 rating, ensuring it is protected against dust and water immersion. It has 8 core strands made from PVC, providing reliable fire behaviour. With stranded conductor strand type and a 26 American Wire Gauge (AWG) it is optimized for applications that demand durability and performance.

General Specification

LAN Category	Cat6
Length	305m
Terminated/Unterminated	Unterminated
Shield Type	F/UTP
Shielded/Unshielded	Shielded
Coding	T568B
Sheath Colour	Grey
Outer Sheath Material	PVC
IP Rating	IP67
Core Strands	8
Fire Behaviour	PVC
Voltage Rating	300V
Conductor Strand Type	Stranded
American Wire Gauge	26AWG

Cable Shape	Round
Number of Strands	8
Outer Diameter (mm)	6mm
Cross Sectional Area (mm)	0.1303mm
Current Rating (A)	2.2A
Applications	Cat6 type cables have primary application use for both home and office computer networks