



Brand of NTN corporation

Technical data

EXFLE205

Bearing units




Grey cast housing, radial insert ball bearing with eccentric locking collar, seal with slinger

KIT CONTENT

EX205G2, FLE205

VISUAL (S)

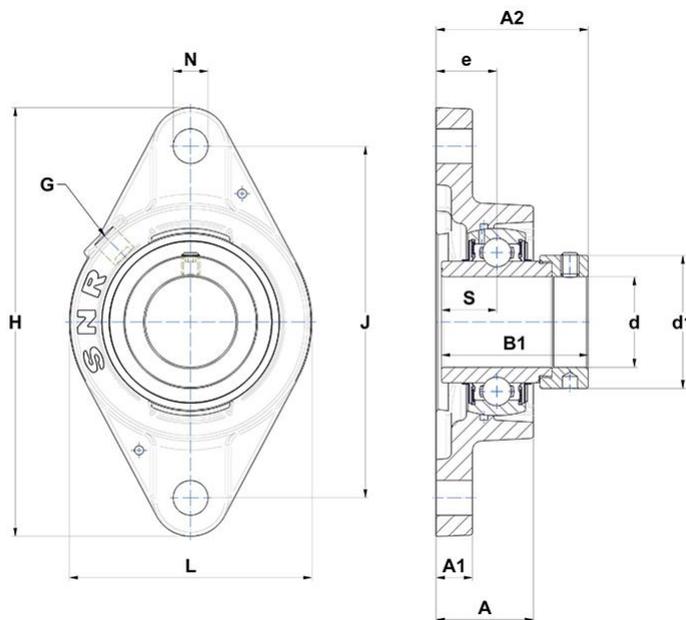

PRODUCT DEFINITION

Brand	SNR
A - Housing height	29,3 mm
A1 - Housing foot height / flange height	11 mm
A2 - Total height from mounting surface	45,9 mm
B - Width of Inner Ring	34,8 mm
B1 - Overall width Inner Ring	44,3 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION

d - Shaft diameter	25 mm
d1 - Outer dia of eccent. Lock. collar / nut of adapter sleeve	37,4 mm
e - Distance mounting surface to bearing center	19 mm
G - Grease fitting	R1/8"
H - Housing length, width or diameter	124 mm
J - Mounting holes distance	99 mm
L - Housing width / diameter	70 mm
N - Mounting hole dimension	11,5 mm
S - Distance front side/bearing centre	17,4 mm

PRODUCT PERFORMANCE

C - Dynamic load rating	14000000 mN
C0 - Static load rating	7880000 mN
Operating temperature min.	253,15 °K
Operating temperature max.	373,15 °K

OTHER FEATURES

Mass	0,65 kg
Recommended tightening torque for set screw	5.5 N-m

