



## 272A - Pump clamp



### Description:

- Capacity: 0 to 1,500 mm.
- Accurate assembly by tightening the pump without rotation.
- Rail treated and notched on edges for clear locking, tilt ball joint.
- Presentation: lacquered, galvanised rail.

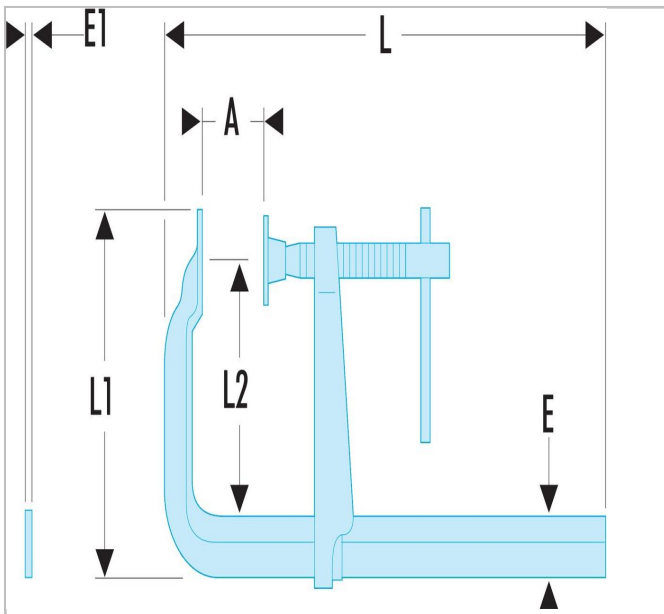

	Depth [mm]	Length L [mm]	Length L1 [mm]	Length L2 [mm]	Thickness E [mm]	Thickness E1 [mm]	open position o maxi [mm]	A Maxi [mm]	Weight [Kg]
<b>272A.1000</b>	100	1100.0	180.0	100	35	9	1000.0	1000.0	
<b>272A.1500</b>	100.0	1600.0	180.0	100.0	35.0	9.0	1500.0	1500.0	5.0
<b>272A.300</b>	80	370.0	150.0	80	30	8	300.0	300.0	
<b>272A.400</b>	80	470.0	150.0	80	30	8	400.0	400.0	
<b>272A.500</b>	80	600.0	150.0	80	30	8	500.0	500.0	
<b>272A.600</b>	100	680.0	180.0	100	35	9	600.0	600.0	
<b>272A.800</b>	100	880.0	180.0	100	35	9	800.0	800.0	