




601-160-1/601-200-1 Combination Pliers



PRODUCT DETAILS

- Combination pliers
- With induction hardened cutting edge for soft and hard wire
- Handles: soft grip bimaterial handles for comfort and control
- Finish: polished
- Material: High performance steel
- Max. cutting edge hardness: 58-65 HRC
- Standard: ISO 5746
- Max. cutting capacity: 1- copper wire, 2- medium hard wire

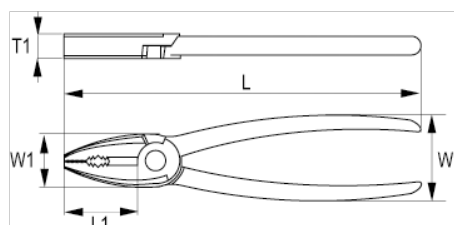

PRODUCT ATTRIBUTES

Product	L	L1	W1	W2	T1			
601-160-1	160 mm	35 mm	24 mm	50 mm	10 mm	1.6 mm	1.0 mm	190 g
601-180-1	180 mm	38 mm	27 mm	50 mm	10 mm	2.0 mm	1.0 mm	240 g
601-200-1	197 mm	41.5 mm	29.5 mm	50 mm	10 mm	2.5 mm	1.0 mm	300 g