

FC22W T9 BL368

Item No: 0000456

SYLVANIA


SpeciaLITE®



Circline 22W UV-A fluorescent lamp for insect attraction and fly traps.

Technical Assets

Dimensions (mm)

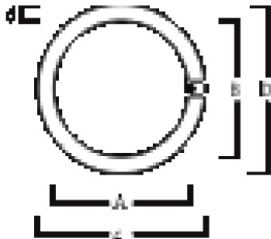

Photometrics

FC22W T9 BL368

Item No: 0000456

SYLVANIA

General data

Product name	FC22W T9 BL368
Technology	Fluorescent
Lamp shape	Ring
Cap/Base	G10q
Lamp finish	Frosted/Coated
Fixture rating	Enclosed
General application	SPG
Operating temperature range (°C)	-20°C...+40°C
ETIM Class	EC002962

Optical data

Light colour	BL368 Blacklight
Adjustable chromaticity	N
Photobiological Risk Group	RG0

Electrical data

Power consumption (W)	22
Wattage (W)	22
Primary Supply/Product voltage - min (V)	230
Primary Supply/Product voltage - max (V)	240
Control gear required	Yes
Dimmable	No
Dimming method	N/A

Lifetime data

Average life (Nominal) (h)	8000
----------------------------	------

Physical data

Nominal Product Height (mm)	149.1
Nominal Product Diameter (mm)	26
Max. Length base to base (mm) - A	149.1
Length base to pin Min-Max (mm) - B	149.1-155.6
Max. Lamp Diameter (mm) - D	26.2
Weight (kg)	0.126

Packaging

Product EAN number	5410288004563
Packaging single length / height (cm)	21.4
Packaging single width (cm)	21.4
Packaging single depth (cm)	3.4
DUN14 (inner)	15410288004560
Units per outer package	12
Packaging outer length / height (cm)	44.9
Packaging outer width (cm)	23.0
Packaging outer depth (cm)	23.5

Safety data

Optimal operating condition (°C)	-20-40
Breakage cleaning instructions	Applicable
Recommendation for disposal at end of life	Applicable
Special purpose lamp	Yes
Intended purpose	Flykilling - Insect attraction
Suitable for household illumination	No
Safety message	Not suitable for household