


**MNX PC 175/75 HT**

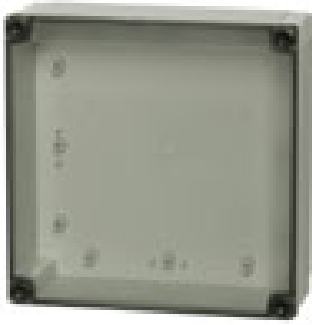

Sample photo

**Order symbol:** PC 175/75 HT  
**Product nbr:** 6011920  
**Description:** Enclosure, PC  
**Remarks:** Smoked transparent cover

**EAN:** 6418074024435  
**EI. number:**  
 Finland: 3422254  
 Electric No. Denmark: 8212022690  
 Electric No. Italy: 7352113  
 Electric No. Sweden: 2535664

Including: Base with TPE gasket, screws for mounting plate/DIN-rail and cover with polyamide cover screws.

**Dimensions:** Length Width Height **Accessories:**

<b>mm:</b>	180	180	75
<b>inch:</b>	7.1	7.1	3.0

MIN 15	DIN-15 Mounting rail
MIV 15	DIN-35 Mounting rail
FP A 175/180	Front plate (Aluminium)
HFP 180	Front plate hinge series
FP 22046	Wall fastening lug (4 pcs)

**Materials:**

<b>Material:</b>	Polycarbonate
<b>Base colour:</b>	RAL 7035 -light grey
<b>Cover screws material:</b>	Polyamide
<b>Cover colour:</b>	Smoked grey
<b>Cover screws colour:</b>	Black
<b>Gasket material:</b>	TPE

**Rating:**

Ingress Protection (EN 60529): IP66/IP67  
 Impact Resistance (EN 62262): IK08  
 Electrical insulation: Totally insulated  
 Halogen free (DIN/VDE 0472, Part 815): 1  
 UV resistance: UL 508  
 Flammability Rating: UL 746C 5"  
 Glow Wire Test (IEC 695-2-1) °C: 960  
 NEMA Class: NEMA 1, 4, 4X, 6, 12, 13

**Temperatures:**

<b>Temperature °C (short term):</b>	-40 ... 120 °C
<b>Temperature °C (continuous):</b>	-40 ... 80 °C
<b>Temperature °F (short term):</b>	-40 ... 250 °F
<b>Temperature °F (continuous):</b>	-40 ... 175 °F

**Certificates:**

SGS Fimko

**Accessories:**

MIV 175 Mounting plate (Galvanized steel)

