



ENCLOSURE FOR 22MM PROGRAM METAL VERSION 2
COMMAND POSITIONS GRAY TOP PART

Enclosure:

model of the measuring transducer		Empty enclosure for command and signaling devices
material / of the housing		metal
Color / of the top part of housing		grey
Number of control points		2
Product component / protective collar		No
Shape / of the housing front		rectangular
Design of electrical connection / on enclosure		Cable routing above, below / left, right, each 1 x M20
Type of mounting / of enclosure		Vertical / horizontal
Product function / EMERGENCY STOP function		No

Actuator / signaling device:

Product component / front ring		No
--------------------------------	--	----

Contact block / lampholder

Product function / positive opening		No
Type of mounting / of contact blocks, socket, and accessories		Floor mounting / front mounting (1-pole)
Product component / fluorescent materials		No
Product extension / optional / fluorescent materials		Yes

Accessories:

Number of labeling plates		2
Product component / holder for 3 switching elements		No

General technical details:

Supply status / pre-wired on terminal strip		No
Product component / stand/pedestal		No
Resistance against shock <ul style="list-style-type: none"> for devices with incandescent lamp / according to IEC 60068-2-27 for devices without incandescent lamp / according to IEC 60068-2-27 		<div><= 30g</div> <div><= 50g</div>
Resistance against vibration / according to IEC 60068-2-6		20 ... 200 Hz: 5g
Item designation <ul style="list-style-type: none"> according to DIN EN 61346-2 according to DIN 40719 extendable after IEC 204-2 / according to IEC 750 		<div>U</div> <div>S</div>
Ambient temperature <ul style="list-style-type: none"> during operating during storage 	<div>°C</div> <div>°C</div>	<div>-25 ... +70</div> <div>-40 ... +80</div>
Protection class IP		IP67
climatic class / during the operating phase / according to EN 60721		3K6
Shape / of the installation hole		round
Mounting diameter	mm	22
Width	mm	85
Height	mm	114
Depth	mm	65

Certificates/approvals:

General Product Approval



Test Certificates

[Special Test Certificate](#)

Shipping Approval



other

[Confirmation](#)

[Environmental Confirmations](#)

Further information:

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/industrial-controls/catalogs>

Industry Mall (Online ordering system)

<http://www.siemens.com/industrial-controls/mall>

Cax online generator:


<http://www.siemens.com/cax>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<http://support.automation.siemens.com/WW/view/en/3SB3802-2AA3/all>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)

http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3SB3802-2AA3

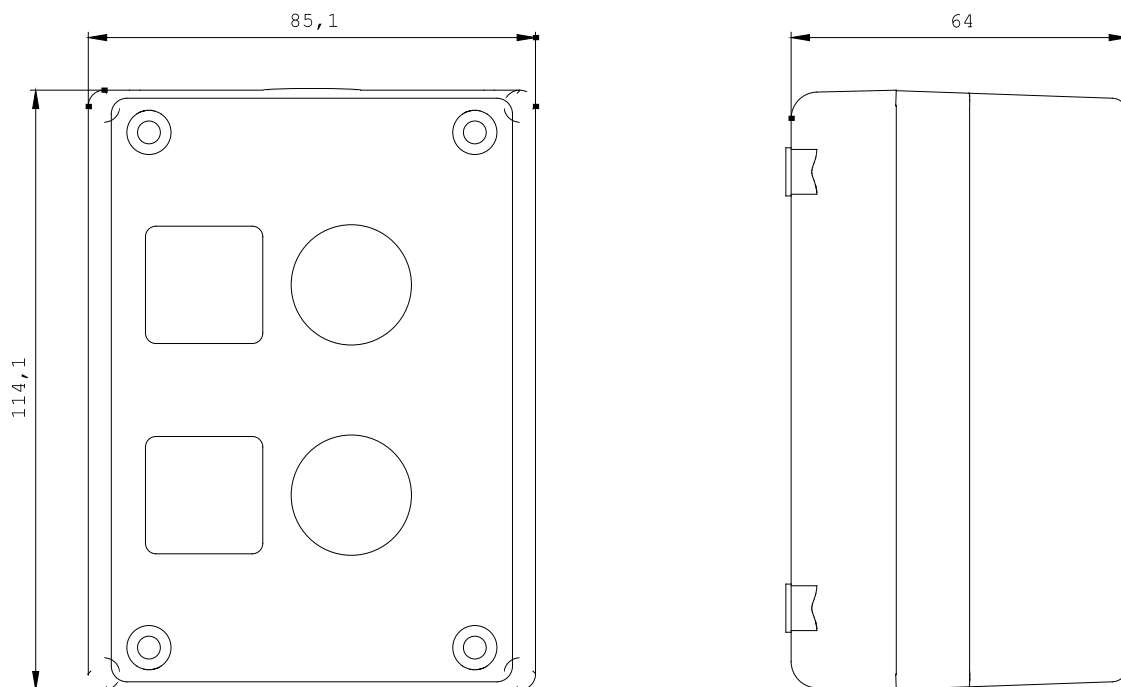

\W9.
\W9.

last change:

Jul 17, 2012