


## Sample Kit Contents

KEMET Part Number	Case Code	Rated Cap	Rated Voltage	DC Leakage	DF	ESR	Quantity
	KEMET	$\mu\text{F}$	VDC	$\mu\text{A @ +25}^\circ\text{C}$ Max/5 Minutes	% @ +25°C 120 Hz Max	m $\Omega$ @ 25°C 100 kHz Max	
T550B127K050AH	B	120	50	45.0	5.0	120	5
T550B756K075AH	B	75	75	42.2	5.0	110	5
T550B107K060AH	B	100	60	45.0	5.0	100	5


## Dimensions – Inches (Millimeters)

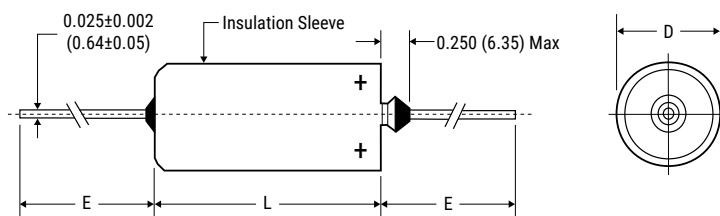

Case Code	Case Size	Uninsulated Case		Insulated Case	
	MIL-PRF-39006/22/25/30/31	L +0.031 (0.79) -0.016 (0.41)	D ±0.016 (0.41)	D Maximum	E ±0.25 (6.35)
B	T2	0.641 (16.28)	0.281 (7.14)	0.312 (7.92)	1.50 (38.10)

## Moisture Sensitivity Notice

These KEMET devices are Moisture Sensitivity Level 3 (MSL3) rated per J-STD-020D. Mass production quantities are packaged in moisture resistant packaging and must be handled per J-STD-020D MSL3 requirements.

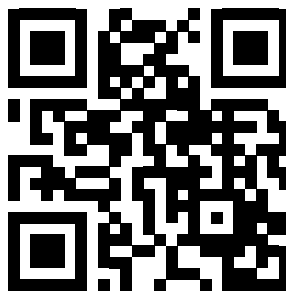

[www.kemet.com/T550](http://www.kemet.com/T550)