


## Automatic lateral wire strippers

### Automatic lateral wire strippers

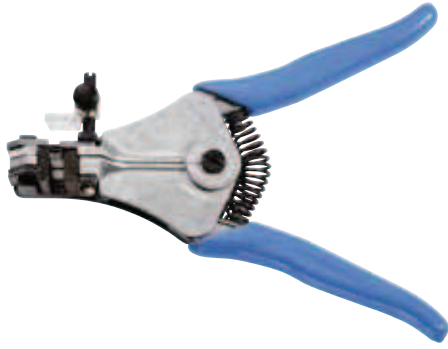


- These strippers offer high precision stripping with a diameter suited to each conductor.

175.E: Spare knife for 986058.

175.T: Spare knife for 986059.

| ⇒             | Pattern   | ΔΔ [g] |
|---------------|---|--------|
| <b>986058</b> | ∅ : 0,6 - 0,8 - 1,0 - 1,2 - 1,6 - 2,0 - 2,5 mm <sup>2</sup> | 370    |
| <b>986059</b> | ∅ : 2,0 - 2,4 - 3,1 - 4,0 mm <sup>2</sup>                   | 370    |

### 165.1 High precision strippers for Teflon insulators

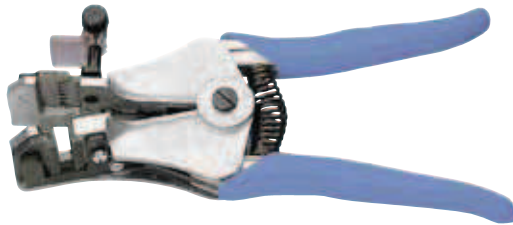

- High precision to cut the insulator circularly without damaging the conductor.
  - Offset jaws designed to avoid marking insulators.
  - AWG: 26 - 24 - 22 - 20 - 18 - 16.
  - Die diameter: 0.55 - 0.65 - 082 - 1.05 - 1.30 - 1.55 mm.
- Weight: 370 g.

165.U: Spare knife.

## Automatic wire cutters-strippers


### 985761 Automatic wire cutter-stripper



- For single or multiple strand with automatic adjustment to wire diameter.
  - 1 tool only, 1 gesture for 2 operations:
    - Cutting.
    - Stripping.
  - Stripping capacity: 0.4 to 4 mm<sup>2</sup>
  - Stripping length adjusted by button: 4 to 17 mm.
  - Cutting diameter: 0.7 to 2.3 mm.
  - AWG: 21 - 11.
  - Length: 160 mm.
- Weight: 340 g.

162-L1: Spare knives.

### 985762 Dual automatic wire cutter-stripper

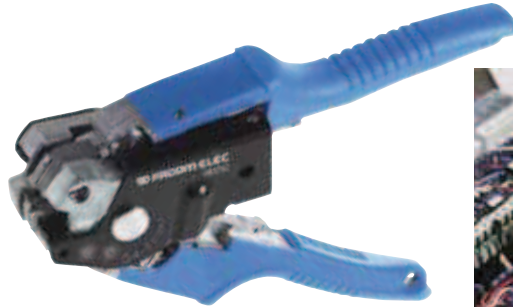

- Allows to cut and strip the wire on both sides for fast wiring operations.
  - The wire is pre-stripped automatically at the right length.
  - Stripping capacity: 0.4 to 4 mm<sup>2</sup>.
  - Stripping length adjusted by button: 4 to 17 mm.
  - Cutting diameter: 0.7 to 2.3 mm.
  - AWG: 21 - 11.
  - Length: 160 mm.
- Weight: 430 g.

162-2L1: Spare knives.