

CV 30/2 BP ADV

Automatic floor detection, brush cleaning function, low ground clearance and surface nozzle: The CV 30/2 Bp Adv is the first battery-powered upright brush-type vacuum cleaner for all carpet and hard surfaces.



Order no. 1.023-206.0

- 300 mm cleaning width, for carpet/hard surfaces, low ground clearance
- 36 V cordless tool, floor detection, brush-cleaning function
- Crevice nozzle, upholstery nozzle, surface nozzle, roller brush

Technical data

EAN code		4054278878218
Battery platform		36 V battery platform
Vacuum	mbar / kPa	187 / 18.7
Air flow	l/s	34
Nominal power	W	420
Sound pressure level	dB(A)	64
Container capacity	l	3
Working width	cm	30
Number of batteries required	Piece(s)	1
Performance per battery charge	m²	200 (6.0 Ah) / 250 (7.5 Ah) ecoefficiency mode: max. 50 (6.0 Ah) / Power mode: max. 32 (6.0 Ah) / ecoefficiency mode: max. 67 (7.5 Ah) / Power mode: max. 47 (7.5 Ah)
Run time per battery charge	min	44 / 68
Battery charging time with quick charger 80% / 100%	min	44 / 68
Power supply for battery charger	V / Hz	100 - 240 / 50 - 60
Colour		anthracite
Weight without accessories	kg	6.5
Weight incl. packaging	kg	9.4
Dimensions (L x W x H)	mm	260 x 310 x 1150

Scope of supply

Versions:	Battery and battery charger not included
Quantity of filter bags:	1 Piece(s)
Crevice nozzle	
Upholstery nozzle	
Surface nozzle	
Roller brush hardness:	medium-soft
Roller brush quantity:	1 Piece(s)
Roller brush colour:	black
Suction tube, removable	
Stretchable suction hose	

Equipment

Filter bag material: Fleece




Automatic floor detection

- Automatic adaptation of cleaning performance to the respective surface.
- Superb cleaning results on textile and hard floors.



Roller brush self-cleaning function using foot switch


- Hairs picked up by the brush are separated and vacuumed.
- Fast, effective cleaning of the roller brush without having to remove it.
- Contactless and therefore particularly hygienic cleaning of the roller brush.

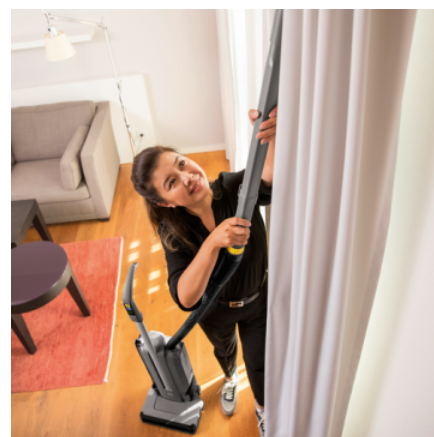

Versatile accessories

- Flexible surface nozzle for cleaning floors, on cabinets and for overhead work.
- Practical upholstery nozzle and crevice nozzle.

**SUSTAINABILITY INFORMATION FROM CV 30/2 BP ADV
1.023-206.0**

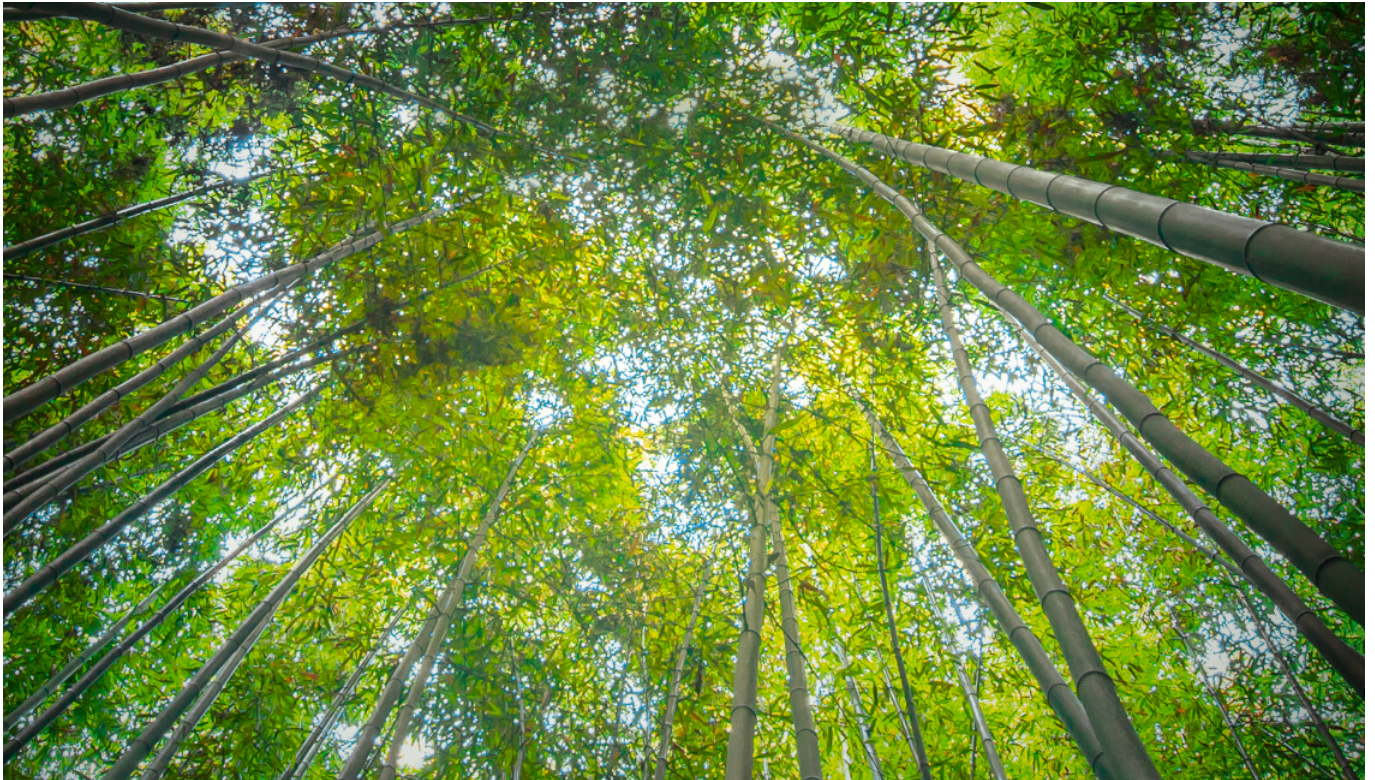

Sustainability features

eco!Mode (Energy Saving Mode)

ACCESSORIES FOR CV 30/2 BP ADV


1.023-206.0



		Order no.	Description	
SUCTION NOZZLES				
Crevice nozzles				
Crevice nozzle, DN 35, plastic, 225 mm long	1	2.889-159.0	Crevice nozzle with nominal width DN 35 for Kärcher dry vacuum cleaners and wet and dry vacuum cleaners. Length 225 mm.	■
Upholstery nozzles				
Upholstery nozzle, DN 35	2	6.905-998.3	Practical plastic upholstery nozzle in DN 35. Ideal for gentle cleaning of upholstered furniture such as sofas, armchairs, upholstered chairs and beds.	■
FURTHER ACCESSORIES DRY VACUUM CLEANERS				
Surface nozzle DN 35 for hard surfaces and carpeted areas	3	2.889-361.0	Innovative surface nozzle with nominal width DN 35 for dry vacuum cleaners from Kärcher. The nozzle can be used on both hard and carpeted surfaces. Working width: 180 mm.	■
Accessories holder CV 30/2 Bp	4	2.889-406.0	Handy accessories holder for the cordless vacuum brush CV 30/2 Bp in DN 35. Suitable for secure storage of up to two accessories during and after cleaning.	□
UPRIGHT BRUSH-TYPE VACUUM CLEANER ACCESSORY				
Roller brush, standard bristles, black, CV 30/2 Bp	5	4.762-644.3	Soft roller brush with black standard bristles made from polyamide, length 255 mm. For all CV 30/2 Bp battery-powered upright brush type vacuum cleaners from Kärcher.	□
BATTERIES				
Battery Power 36/50	6	2.445-031.0	36 V / 5.0 Ah Battery Power exchangeable battery with innovative Real Time Technology incl. LCD display to show the battery level. Suitable for all devices on the 36 V Kärcher battery platform.	□
BATTERY CHARGERS				
Fast Charger Battery Power 36 V	7	2.445-033.0	With the fast charger, the 36 V/2.5 Ah exchangeable battery can be charged to 80% in just 48 minutes. Also suitable for all other batteries on the 36 V Kärcher battery platform.	□
STARTERKIT BATTERIES AND BATTERY CHARGERS				
Starter kit Battery Power 36/50	8	2.445-065.0	Battery Power 36/50 Starter Kit incl. 36 V/5.0 Ah Battery Power exchangeable battery and 36 V fast charger. Suitable for use in all devices on the 36 V Kärcher battery platform.	□
BATTERIES				
Battery Power+ 36/75	9	2.445-043.0	A capacity of 7.5 Ah guarantees long runtimes for the Battery Power+ 36 V lithium-ion battery. Very powerful, with Real Time Technology via LCD display and protection against overcurrent.	□
Battery Power+ 36/60	10	2.042-022.0	Extremely powerful Battery Power+ 36 V lithium-ion battery with a capacity of 6.0 Ah for a long runtime. With innovative Real Time Technology via LCD display and voltage monitoring.	□
BATTERY CHARGERS				
Universal charger Battery Power+ 18-36	11	2.445-054.0	Universal charging unit Battery Power+ with LED operating status indicator for charging all 18 and 36 V Kärcher Battery Power and Kärcher Battery Power+ lithium-ion batteries. Suitable for wall mounting.	□
Fast charger Battery Power+ 36/60	12	2.445-045.0	Charge all 36 V Kärcher Battery Power and Kärcher Battery Power+ lithium-ion batteries with max. 6 A charging current: Quick charger with LED operating status indicator. Easy wall mounting.	□
STARTER KIT				
Starter kit Battery Power+ 36/75	13	2.445-070.0	Starter Kit Battery Power+ 36/75 with 2 36-V/7.5-Ah batteries and 36-V quick charger for our 36 V Kärcher Battery Power and Kärcher Battery Power+ battery platform devices.	□
Starter kit Battery Power+ 36/60	14	2.445-071.0	Kärcher Battery Power+ 36/60 Starter Kit for all machines in the Kärcher 36 V Battery Power+ battery platform. Scope of delivery: 2x 36 V/6.0 Ah batteries and the compatible 36 V quick charger.	□

■ Included in the scope of supply. □ Available accessories.

ACCESSORIES FOR CV 30/2 BP ADV
1.023-206.0

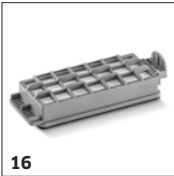

		Order no.	Description	
FILTER BAGS				
Fleece filter bags				
Fleece filter bags, 10 Piece(s), CV 30/2 Bp	15	2.889-357.0	Tear-resistant 3-layer fleece filter bags of dust class M for use with Kärcher battery-powered CV 30/2 Bp upright brush-type vacuum cleaners. Contents: 10-pack.	☐
FILTER T/ NT				
HEPA Filter				
HEPA-14 filter for BVL 3/1 Bp, BVL 5/1 Bp and CV 30/2 Bp	16	2.889-342.0	Increases the filter capacity and improves the blower air: The highly effective HEPA 14 filter offers a separation degree of 99.995% and is certified according to test standard DIN EN 1822:2019.	☐

☐ Available accessories.