



fitted with

work equipment
 connected load
 power consumption
 luminous flux
 luminous efficacy
 light distribution
 Beam Angle
 light colour
 color rendering index (CRI)
 system of protection
 class of protection
 technology
 usage
 luminaire body
 lamp cover
 tubular sections
 balance of articulation joints
 weight (net)
 mains lead

LED

Energy efficiency category A+
 electronic plug-in transformer
 100-240 V; 50/60 Hz
 approx. 7 W
 approx. 400 lm
 approx. 57 lm/W
 direct, narrow-angled beam
 9
 daylight white, approx. 5700 K
 > 72
 IP 20 (65)
 II
 switchable
 switch
 aluminium, anodised, black
 glass screen
 flexible metal tube, Jet black
 friction
 approx. 1.6 kg
 approx. 2.7 m; mains plug
 BS 1363
 CEE 7/XVI
 NEMA 1-15P

fastening

screw-down flange, magnetic base (accessory), table clamp (accessory), wall bracket (accessory)

accessory

Interchangeable mains plug

special features

Spot with a 10° angle of radiation



BS 1363




CEE 7/XVI



NEMA 1-15P

illuminance

distance: 50 cm
 Em: 4086 lx
 Emax: 27500 lx
 Emin: 440 lx

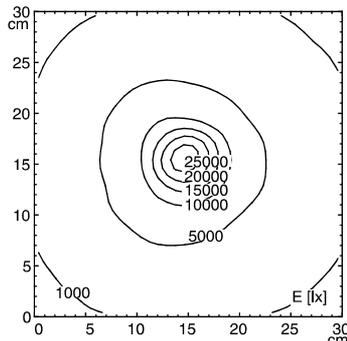

luminous intensity

