




TAH1RM-19

Ratcheting Combination Wrench with Safety Spring 19 mm



PRODUCT DETAILS

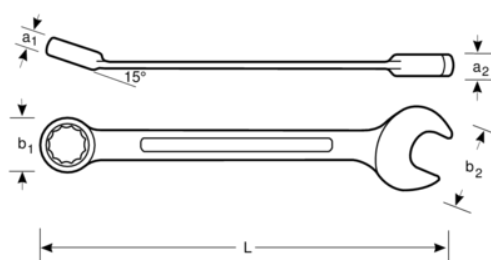

- Larger, bi-directional, size marking for easy identification
- 12-Point Dynamic-Drive™ profile provides longer life for screws and nuts
- Chrome micro-matte finishing
- High-performance alloy steel
- Offset and slim head to get more accessibility
- Ratchet in the ring for high productivity application
- Suitable for working at height
- Permanent stainless steel sliding spring maintains user ergonomics and full functionality
- Colour plates with maximum weight for a right matching with the lanyard
- According to DROPS best practices



Follow the Fish!



PRODUCT ATTRIBUTES

Product		L	a1	a2	b1	b2	
TAH1RM-19	19 mm	248 mm	11.2 mm	8.8 mm	33.8 mm	39.7 mm	233 g

