

## D-SUB cable - VS-15-DSUB-20-LI-2,0 - 1656275

Please be informed that the data shown in this PDF Document is generated from our Online Catalog. Please find the complete data in the user's documentation. Our General Terms of Use for Downloads are valid (<http://phoenixcontact.com/download>)



Assembled D-SUB cable shielded, 15-pos., stranded (7-wire), cable color RAL 7000 (gray), IP20 degree of protection, head 1 with socket shell 2 and straight cable outlet, head 2 with pin shell 2 and straight cable outlet, length: 2 m

### Key Commercial Data

Packing unit	1 pc
GTIN	
GTIN	4046356029759
Weight per Piece (excluding packing)	184.700 g
Custom tariff number	85444290
Country of origin	China

### Technical data

#### Mechanical characteristics

Number of positions	15
Insertion/withdrawal cycles	≥ 50
Cable outlet	straight
Degree of protection	IP20

#### Ambient conditions

Ambient temperature (operation)	0 °C ... 70 °C
Degree of protection	IP20

#### Material data

Housing material	PVC
Contact material	Copper alloy
Contact surface material	gold-plated
Outer sheath, material	PVC

#### Electrical characteristics

# D-SUB cable - VS-15-DSUB-20-LI-2,0 - 1656275

## Technical data

### Electrical characteristics


Number of positions	15
Rated current	1 A
Overvoltage category	III
Degree of pollution	2
Rated voltage (III/3)	125 V

### Environmental Product Compliance


China RoHS	Environmentally friendly use period: unlimited = EFUP-e
	No hazardous substances above threshold values

## Drawings


Dimensional drawing

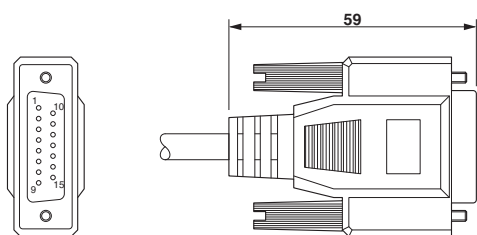


Dimensional drawing

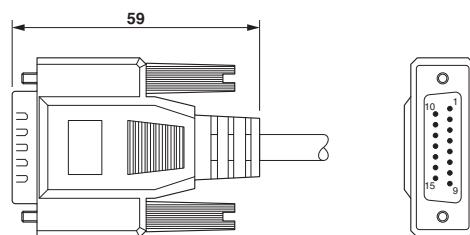


Circuit diagram

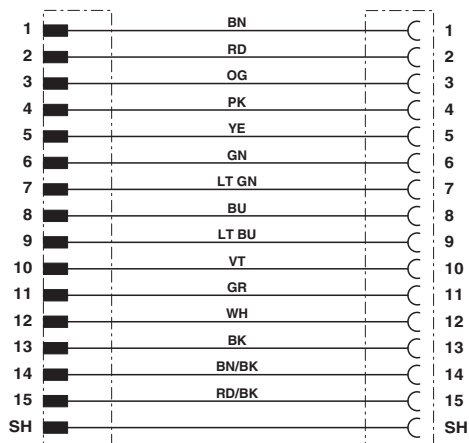

Schematic diagram

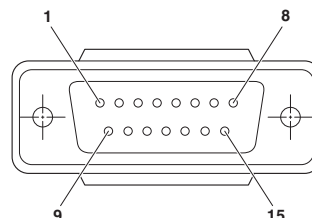

Schematic diagram

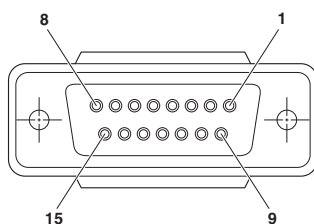

# D-SUB cable - VS-15-DSUB-20-LI-2,0 - 1656275

## Classifications

### eCl@ss

eCl@ss 10.0.1	27060390
eCl@ss 4.0	27060306
eCl@ss 4.1	27060306
eCl@ss 5.0	27061801
eCl@ss 5.1	19030300
eCl@ss 6.0	27060300
eCl@ss 7.0	27060390
eCl@ss 8.0	27060390
eCl@ss 9.0	27060390

### ETIM

ETIM 2.0	EC000830
ETIM 3.0	EC001855
ETIM 4.0	EC001855
ETIM 5.0	EC001408
ETIM 7.0	EC000748

### UNSPSC

UNSPSC 6.01	31261501
UNSPSC 7.0901	31261501
UNSPSC 11	31261501
UNSPSC 12.01	31261501
UNSPSC 13.2	26121604

## Approvals

### Approvals

---

Approvals


EAC / EAC

---

Ex Approvals

---

### Approval details

EAC		B.01742
-----	---	---------

## D-SUB cable - VS-15-DSUB-20-LI-2,0 - 1656275

### Approvals

EAC



B.00767