



Double-ended ring spanners, imperial, extra long

220a



Product no. 41431416
GTIN 4018754156771
Model 220a 7/32 x 1/4



Label.

Double-ended ring spanner Size 7/32 x 1/4 " L.184mm

Properties.

- imperial, differing end sizes
- cranked 15°
- bi-hex with AS-Drive profile
- extra long design for less effort with constant torque
- suitable for working in confined spaces
- durable, slim and lightweight design
- high flexural strength due to double-T profile
- STAHLWILLE's rounded finish ensures a non-slip, pleasant feel
- HPQ® high performance steel, chrome-plated
- SAE AS 954-E (test values)

Benefits.

High quality double-ended ring spanner with an extra long design for better power transmission.

Product highlights.



Extra-long design.

The spanner is ideal for working on hard-to-reach screw points due to its extended design and enables high torques for better power transmission when tightening.

Technologies and features.



High Performance Quality (HPQ®)

Our HPQ® tool is made of wear-resistant high-performance steel, yet is thin-walled and lightweight. It withstands high torques and is ideal for work in confined spaces such as turbines.



Anti-Slip-Drive


The special AS-Drive profile makes high force transmission to the flats of bolts and nuts possible without damaging them. This also prevents stripping of the screw head.



Thin-walled rings

The thin-walled diameter of our rings makes it easier to work in confined spaces. The ring wall is deeper than standard nuts, which prevents jamming.

Technical drawing.

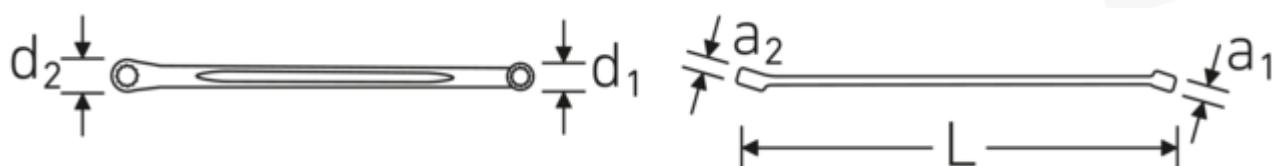

Technical attributes.

a1	5,3 mm
a2	5,8 mm
Drive profile	bi-hex AS-Drive
d1	9 mm
d2	9,9 mm
Length mm (L)	184 mm

Logistics data.

Depth mm (IFS)	184
Width mm (IFS)	10
Height mm (IFS)	7
WEEE/ElektrOg	nicht ear-pflichtig
Length (packaged, mm)	200
Width (packaged, mm)	30
Height (packaging, mm)	11

Alloy	HPQ® high performance steel	Volume (packaged, dm3)	0.066 dm3
Surface	chrome-plated	Product no.	41431416
Ring position	15 °	Weight (gross, kg)	0,153
Size 1 [inch]	7/32 "	Weight PAP (kg)	0,000
Size 2 [inch]	1/4 "	Weight PVC (kg)	0,004
		GTIN	4018754156771
		Country of origin AWR	GERMANY
		Region of origin	Nordrhein-Westfalen
		Customs tariff no.	82041100
		Packing standard	5
		Weight (g)	29 g

Variants.

Product no.	Model No. (ERP)	Description	GTIN
41431416	220a 7/32 x 1/4	Double-ended ring spanner Size 7/32 x 1/4 " L.184mm	4018754156771
41431620	220a 1/4 x 5/16	Double-ended ring spanner Size 1/4 x 5/16 " L.205mm	4018754156788
41432428	220a 3/8 x 7/16	Double-ended ring spanner Size 3/8 x 7/16 " L.250mm	4018754156795
41433234	220a 1/2 x 9/16	Double-ended ring spanner Size 1/2 x 9/16 " L.290mm	4018754156801
41433640	220a 5/8 x 3/4	Double-ended ring spanner Size 5/8 x 3/4 " L.363mm	4018754156818
41433840	220a 11/16 x 3/4	Double-ended ring spanner Size 11/16 x 3/4 " L.365mm	4018754156825

GTIN.



4 018754 156771

STAHLWILLE Eduard Wille GmbH

Lindenallee 27 · 42349 Wuppertal · Germany · Phone: +49 202 4791-0

info@stahlwille.de · www.stahlwille.com

© STAHLWILLE Eduard Wille GmbH, Wuppertal