



# Datasheet

## Stock No. 1881770, 1882212

### RS PRO Piezo Buzzer



ENGLISH



#### Specifications



|                       |            |
|-----------------------|------------|
| Rated voltage         | 12VDC      |
| Operating voltage     | 1-18VDC    |
| Rated current*        | ≤20mA      |
| Sound output at 10cm* | ≥85dB      |
| Resonant frequency*   | 4000±500Hz |
| Tone                  | Continuous |
| Operating temperature | -30~+70°C  |
| Storage temperature   | -40~+85°C  |
| Weight                | 2.5g       |

\*Value applying at rated voltage (DC)

All data at 25°C unless otherwise specified

#### Features

- ROHS compliant
- Lead pin material: Red Copper
- Housing material: Noryl
- Wave solderable but not washable

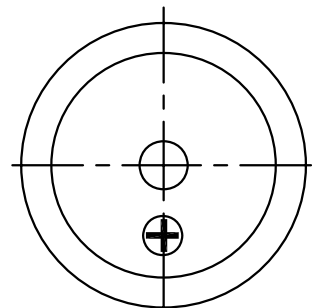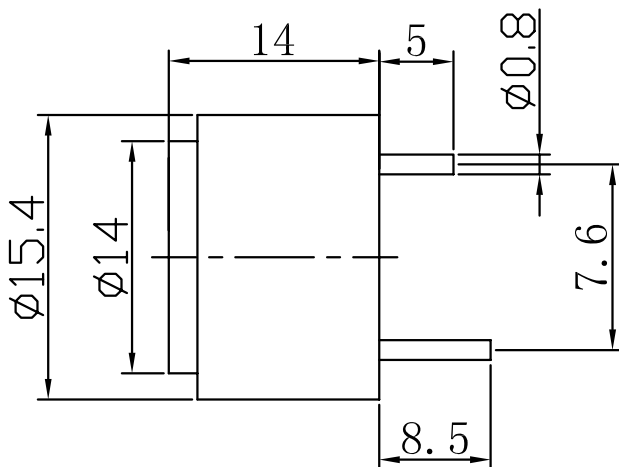

Dimensions Unit: mm Tolerance: ±0.5mm