



Product Compliance

For compliance documentation, visit the product page on TE.com>


EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2025 (247) Candidate List Declared Against: JAN 2025 (247) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer


This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



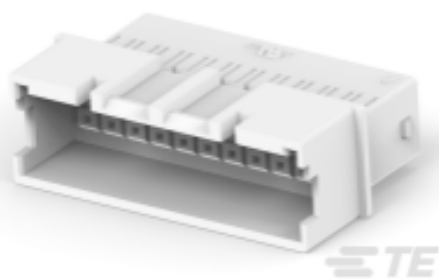

TE Part # 2-2324582-2
HSG,REC,FREE-HANGING,DUALROW,EP2.5

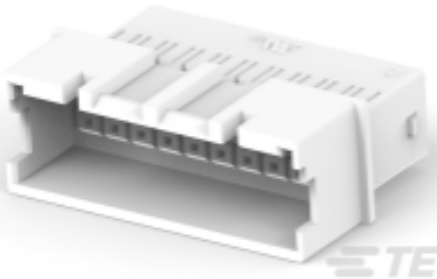


TE Part # 2-2324582-0
HSG,REC,FREE-HANGING,DUALROW,EP2.5




TE Part # 1969592-8
HSG,REC,FREE-HANGING,DUALROW,EP2.5




TE Part # 1-1969540-2
HOUSING, PLUG, 12P, DUAL ROW, EP2.5

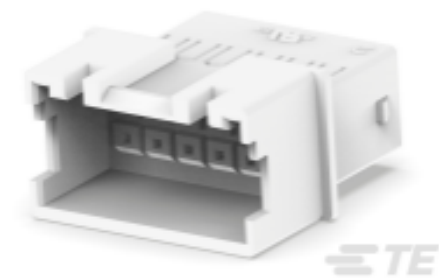

TE Part # 1-2324582-2
HSG,REC,FREE-HANGING,DUALROW,EP2.5

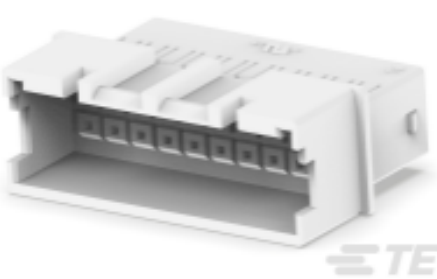

TE Part # 1-2324582-8
HSG,REC,FREE-HANGING,DUALROW,EP2.5

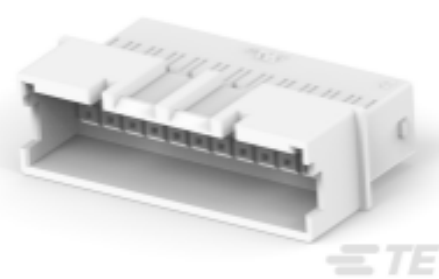

TE Part # 2-2324582-4
HSG,REC,FREE-HANGING,DUALROW,EP2.5


Customers Also Bought




TE Part #1461492-5
OJT-SS-112LM,000 RELAY



TE Part #1643903-1
CROWN CLIP Senior II 538-0068-00100

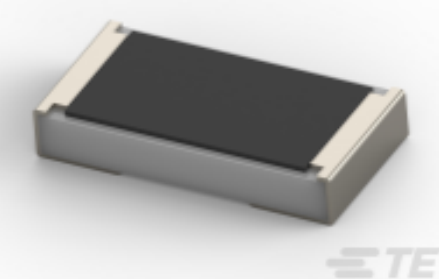

TE Part #2176469-1
TLRP 2010 2.0W R010 1% 75PPM 4K RL

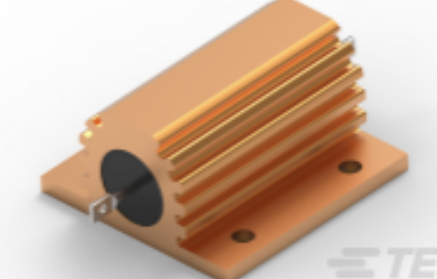


TE Part #CAT-C339-H85913
Power Resistors: Aluminum Housed, HSA




TE Part #T2071104101-000
H10BP-T3-M DOCKING FRAME_FLOATING



TE Part #T2111028101-000
HMN-D2-MC

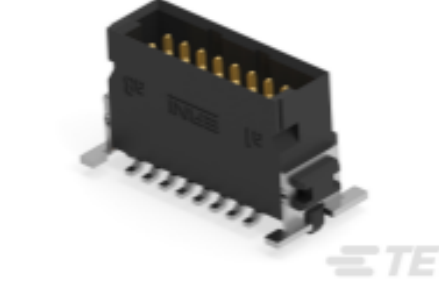

TE Part #254536-E
SMCQ 16 M AB VV 8-03 CL * H007 137 E005

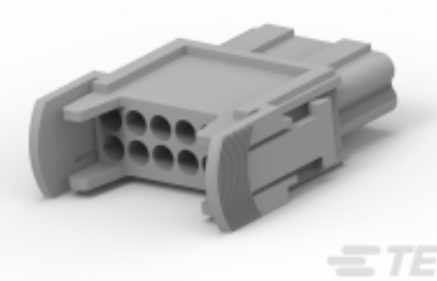

TE Part #T2111122201-000
HMN-012-F



TE Part #T2071104201-000
H10BP-T3-F DOCKING FRAME_FIXED

Documents



Product Drawings

HSG,REC,FREE-HANGING,DUALROW,EP2.5

English

CAD Files

3D PDF

3D

Customer View Model

ENG_CVM_CVM_1-1969592-2_A.2d_dxf.zip

English

Customer View Model

ENG_CVM_CVM_1-1969592-2_A.3d_igs.zip

English

Customer View Model

ENG_CVM_CVM_1-1969592-2_A.3d_stp.zip

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Datasheets & Catalog Pages

7-1773461-6_EP2.5_Connector_Series

English

Product Specifications

Application Specification

English

Instruction Sheets

Instruction Sheet (U.S.)

English

Agency Approvals

VDE Certificate

English