

**ENGINEERS' HAMMERS ROTBAND-PLUS**

600 E + 600 H

**ENGINEERS' HAMMER ROTBAND-PLUS**

- ▶ Forged hammer head DIN 1041
- ▶ With contoured ash or hickory handle DIN 5111, additionally shaped with a long hardened handle protective steel sleeve
- ▶ The tapered collar, fixing plate and wood screw bond the hammer head and the handle into one unit
- ▶ Patented handle join, high working safety, long service life, best price-performance ratio
- ▶ DBGM G 9414 1878 (German utility patent), European-Patent-No. 0703045



g	l mm	kg	Code	No.
100	260	0.188	8581610	600 E-100
200	280	0.325	8581880	600 E-200
300	300	0.502	8581960	600 E-300
400	310	0.605	8582180	600 E-400
500	320	0.727	8582260	600 E-500
600	330	0.841	8582340	600 E-600
800	350	1.135	8582420	600 E-800
1000	360	1.326	8582500	600 E-1000
1500	380	1.908	8582690	600 E-1500
2000	400	2.491	8582770	600 E-2000

g	l mm	kg	Code	No.
100	260	0.188	8582850	600 H-100
200	280	0.325	8582930	600 H-200
300	300	0.502	8583070	600 H-300
400	310	0.605	8583150	600 H-400
500	320	0.727	8583230	600 H-500
600	330	0.840	8583310	600 H-600
800	350	1.135	8583580	600 H-800
1000	360	1.326	8583660	600 H-1000
1500	380	1.908	8583740	600 H-1500
2000	400	2.491	8583820	600 H-2000



600 IH

**ENGINEERS' HAMMER ROTBAND-PLUS**

- ▶ Forged hammer head DIN 1041
- ▶ The edges of the flat side of the head are induction hardened
- ▶ With contoured ash or hickory handle DIN 5111, additionally shaped with a long hardened handle protective steel sleeve
- ▶ The tapered collar, fixing plate and wood screw bond the hammer head and the handle into one unit
- ▶ Patented handle join, high working safety, long service life, best price-performance ratio




g	l mm	kg	Code	No.
200	280	0.325	8583900	600 IH-200
300	300	0.502	8584040	600 IH-300
400	310	0.605	8584120	600 IH-400
500	320	0.727	8584200	600 IH-500
600	330	0.841	8584390	600 IH-600
800	350	1.135	8587300	600 IH-800
1000	360	1.326	8587490	600 IH-1000
1500	380	1.908	8587570	600 IH-1500



1500 ES-350 / 1500 CT1-350

104 · 110

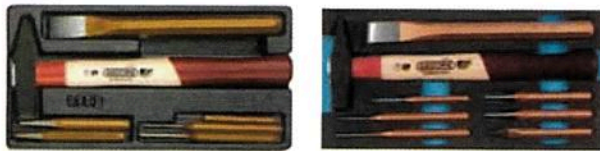

6 NA

483

