



Brand of NTN corporation


## Technical data

### BBE30UU-AJ

Standard ball bushings adjustable



#### VISUAL (S)

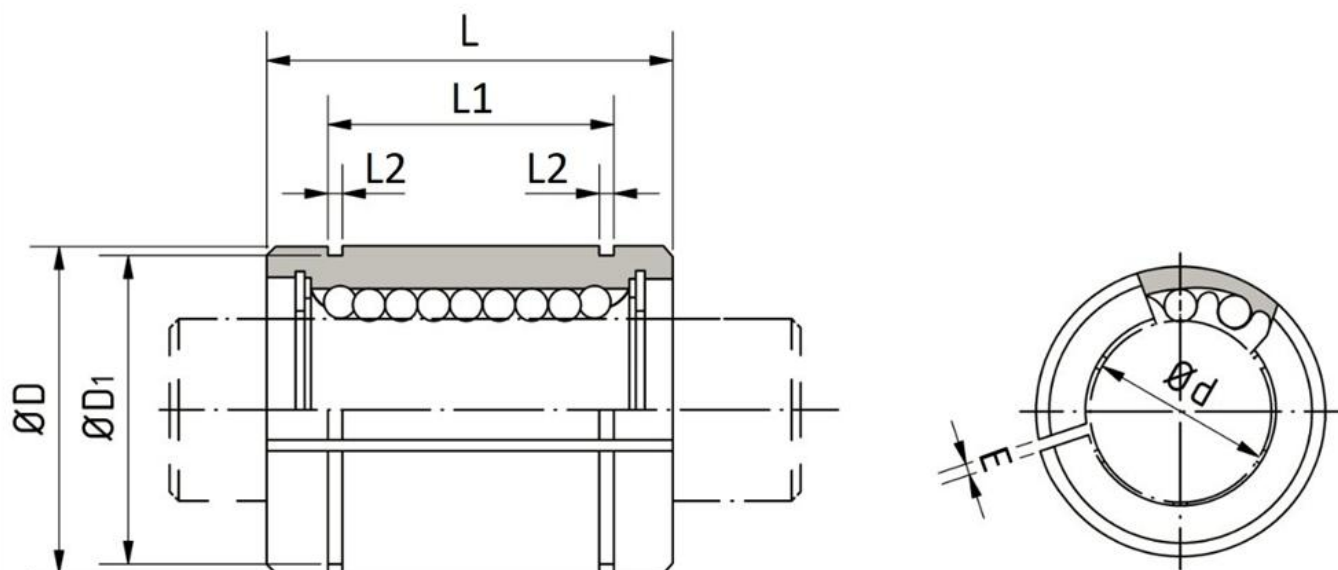

#### PRODUCT DEFINITION

|                                           |                                    |
|-------------------------------------------|------------------------------------|
| Brand                                     | SNR                                |
| Design type                               | BBE-AJ                             |
| Ball bushings category                    | Standard ball bushings, adjustable |
| Standard                                  | ISO dimension                      |
| Number of seals                           | 2                                  |
| Material outer cylinder or steel segments | 100Cr6                             |
| Material Cage                             | PA                                 |
| Initial greasing                          | Non/No                             |
| d - Internal diameter                     | 30 mm                              |



#### NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00  
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072  
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

| PRODUCT DEFINITION                     |              |
|----------------------------------------|--------------|
| <b>d - Internal diameter tolerance</b> | 0,011/-0;001 |
| <b>D - External diameter</b>           | 47 mm        |
| <b>D - External diameter tolerance</b> | 0/-0,011     |
| <b>L - Length</b>                      | 68 mm        |
| <b>L - Length tolerance</b>            | 0/-0,3       |
| <b>L1</b>                              | 52,1 mm      |
| <b>L1 tolerance</b>                    | 0/-0,3       |
| <b>D1 - Diameter</b>                   | 44,5 mm      |
| <b>L2</b>                              | 1,85 mm      |
| <b>E</b>                               | 2 mm         |
| <b>Number of ball rows</b>             | 6            |
| <b>Mass</b>                            | 0,355 kg     |

| PRODUCT PERFORMANCE                     |          |
|-----------------------------------------|----------|
| <b>Cmin</b>                             | 1,584 kN |
| <b>Cmax</b>                             | 2,028 kN |
| <b>C0min</b>                            | 2,74 kN  |
| <b>C0max</b>                            | 3,507 kN |
| <b>Tmin - Min operating temperature</b> | -20 °C   |
| <b>Tmax - Max operating temperature</b> | 80 °C    |

| ESHOPDONOTDISPLAY    |                            |
|----------------------|----------------------------|
| <b>Reference</b>     | BBE30UU-AJ                 |
| <b>Image</b>         | BBE-AJ_1.JPG, BBE-AJ_3.JPG |
| <b>Send to Eshop</b> | Yes                        |



BBE30UU-AJ  
Standard ball bushings adjustable

| ESHOPDONOTDISPLAY     |         |
|-----------------------|---------|
| Send to Paper Catalog | Yes     |
| Tracepart             | Oui/Yes |

