

START Panel Flat 600x600

 
START Panel Flat 600x600 HE 4300Lm 840

0047215



Product features

- Edge lit LED flat panel. Low Flicker, 35 W, Neutral White, 4000 K, 4300 lumens, high efficacy, 123 lm/W, 50000 hours lifetime (L70), PMMA opal diffuser, aluminium frame, steel body, electronic non dimmable driver. (HxWxD) 9.5 x 595 x 595 mm




PRODUCT OVERVIEW

IPC Code	0047215
Product name	START Panel Flat 600x600 HE 4300Lm 840
Technology	LED
Housing	Aluminium
Mount	Surface/Recessed/Suspended
General application	Office
Certifications	EUNEW008
ETIM Class	EC002892
Fixture luminous flux (lm)	4,350
Luminaire efficacy (lm/W)	124
Colour temperature (K)	4000
CRI (Ra)	80
Colour Variation Initial (SDCM)	5
Beam Angle (°)	120
Glare control	N/A
Photobiological Risk Group	RG0
Total power consumption (W)	35
Electrical protection	Class II
Control gear type	Electronic (constant current)
Dimmable	No
LED Flickering Rate	Ultra low (5% or less)
Average life (Nominal) (h)	50000
Housing colour	RAL9003
IP rating	IP40/20
IK rating	IK03
Product EAN number	5410288472157
Lamps	No

PHOTOMETRY

START Panel Flat 600x600

START Panel Flat 600x600 HE 4300Lm 840
0047215

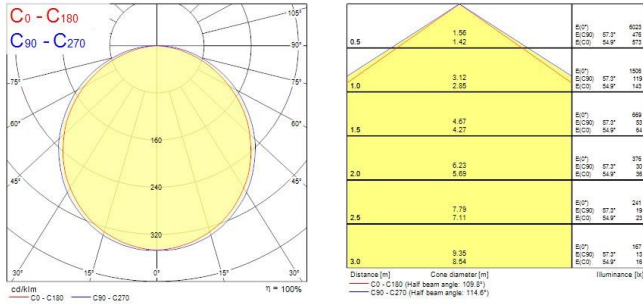

TECHNICAL DRAWINGS

