




624-140-1/624-180-1 Side Cutting Pliers



PRODUCT DETAILS

- Side cutting pliers
- With induction hardened cutting edge for soft and hard wire
- Handles: soft grip bimaterial handles for comfort and control
- Finish: polished
- Material: High performance steel
- Max. cutting edge hardness: 60-65 HRC
- Standard: ISO 5749
- Max. cutting capacity: 1- copper wire, 2- medium hard wire

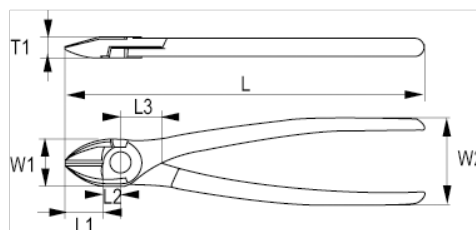

PRODUCT ATTRIBUTES

Product	L	L1	L2	L3	W1	W2	T1			
624-140-1	142 mm	20.5 mm	6 mm	12 mm	18.6 mm	50 mm	10 mm	1.6 mm	0.5 mm	170 g
624-160-1	160 mm	21.5 mm	7 mm	13 mm	21.6 mm	50 mm	11.5 mm	1.6 mm	0.5 mm	200 g
624-180-1	176 mm	24.5 mm	7 mm	14 mm	25.6 mm	50 mm	12.5 mm	1.6 mm	0.5 mm	250 g