

113A.CG - CHROMED SHEATH ADJUSTABLE WRENCHES | 113A.4CG




Norm :

NF ISO 6787, ISO 6787, DIN 3117, ASME B107.100

Description

- Good access to the button = easy setting.
- Non-protruding moving jaw at maximum capacity.
- Pre-adjustment of jaw opening thanks to millimetric gradation.
- Right-hand button rotation.
- Range from 4" to 12".
- Presentation: sheathed chromed body and polished head faces.

Information

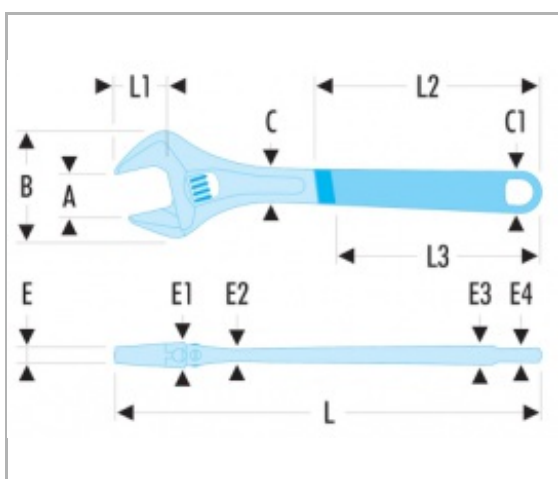

A [mm]	13
B [mm]	34,0
C1 [mm]	18,5
E [mm]	4,5
E1 [mm]	9,5
E2 [mm]	5,0
E3 [mm]	9,5
E4 [mm]	6,0
L [mm]	116
L1 [mm]	13
L2 [mm]	65,5
[g]	75

