


# E12639



## Connector

SPLITTER CABLE END CAP 4p

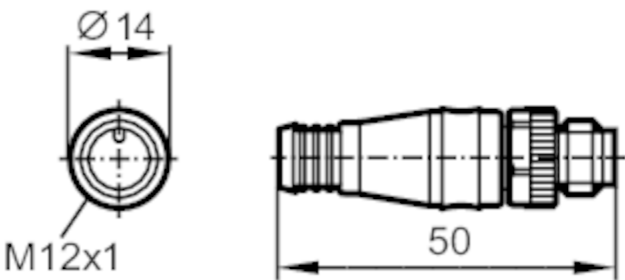

| Application                  |      |                                          |
|------------------------------|------|------------------------------------------|
| Special feature              |      | Free from silicone; Gold-plated contacts |
| Free from silicone           |      | yes                                      |
| Electrical data              |      |                                          |
| Operating voltage            | [V]  | < 30 AC / < 36 DC                        |
| Max. current load total      | [A]  | 4                                        |
| Operating conditions         |      |                                          |
| Ambient temperature          | [°C] | -25...85                                 |
| Ambient temperature (moving) | [°C] | > -15                                    |
| Protection                   |      | IP 67                                    |
| Mechanical data              |      |                                          |
| Weight                       | [g]  | 16.4                                     |
| Dimensions                   | [mm] | Ø 14 / L = 50                            |
| Moulded-body material        |      | TPU, Halogen-free                        |
| Material nut                 |      | brass, nickel-plated                     |
| Remarks                      |      |                                          |
| Pack quantity                |      | 1 pcs.                                   |

# E12639



## Connector

SPLITTER CABLE END CAP 4p

### Electrical connection

Connector: M12; coding: A; Moulded body: TPU, Halogen-free; Locking: brass, nickel-plated; Contacts: gold-plated; Tightening torque: 1 Nm



### Connection

