 
 
 
 



Receptacle combinations, pre-wired for installation

Enclosure and insert made of **Amaplast**.

Combinations can also be supplied with SCHUKO® type receptacles 16A, 230V, 2P+E or French/Belgian, British, Danish and Swiss standards:



Protection type Δ IP 44

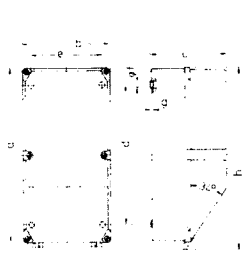

a	341
b	172
c	149
d	272
e	140
f	8,5
g	6,5
h	355
Dim. in mm	


Other variations on request!

Cable entry:


2 x Pg 29 open at the top

2 x Pg 29 plugged at the bottom

This drawing is applicable for products on pages 121 and 122

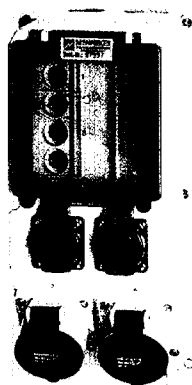


2 CEEform receptacles 16A, 400V, 5P
2 SCHUKO® type receptacles 16A, 230V, 2P+E
Fuse/protection:
2 Neozed D 01, 3P
2 Neozed D 01, 1P
Preferably with connection for 2 cables of up to 5x25 mm²
Part No. 97997

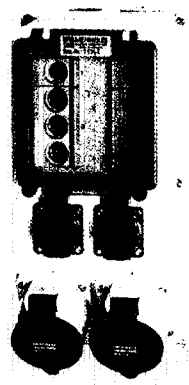


2 CEEform receptacles 32A, 400V, 5P
2 SCHUKO® type receptacles 16A, 230V, 2P+E
Fuse/protection:
2 Neozed D 02, 3P
2 Neozed D 01, 1P
Preferably with connection for 2 cables of up to 5x25 mm²
Part No. 98066




6

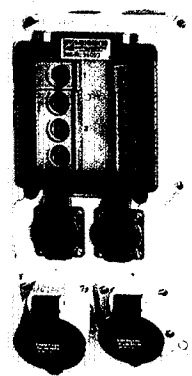


1 CEEform receptacle 16A, 400V, 5P
1 CEEform receptacle 32A, 400V, 5P
2 SCHUKO® type receptacles 16A, 230V, 2P+E
Fuse/Protection:
1 Neozed D 01, 3P
1 Neozed D 02, 3P
2 Neozed D 01, 1P
Preferably with connection for 2 cables of up to 5x25 mm²
Part No. 98093

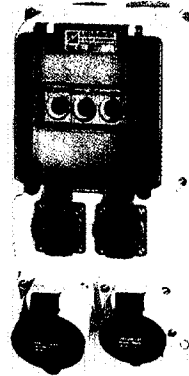

1 CEEform receptacle 16A, 400V, 5P
1 CEEform receptacle 32A, 400V, 5P
2 SCHUKO® type receptacles 16A, 230V, 2P+E
Fuse/protection:
1 Neozed D 01, 3P
1 Neozed D 01, 1P
Preferably with connection for 2 cables of up to 5x25 mm²
Part No. 98072

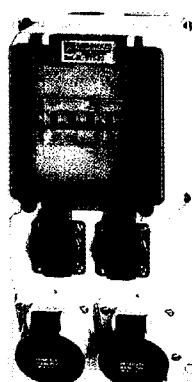

2 CEEform receptacles 16A, 400V, 5P
2 SCHUKO® type receptacles 16A, 230V, 2P+E
Fuse/protection:
2 MCBs 16A, 3P, K
2 MCBs 16A, 1P, B
Preferably with connection for 2 cables of up to 5x25 mm²
Part No. 97981

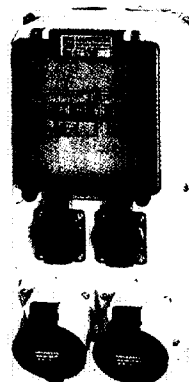

2 CEEform receptacles 32A, 400V, 5P
2 SCHUKO® type receptacles 16A, 230V, 2P+E
Fuse/protection:
2 MCBs 32A, 3P, K
2 MCBs 16A, 1P, B
Preferably with connection for 2 cables of up to 5x25 mm²
Part No. 95338

 
 
 
 
As above, but with fuse/protection:
2 MCBs 16A, 3P, C
2 MCBs 16A, 1P, B
Part No. 97580

As above, but with fuse/protection:
2 MCBs 32A, 3P, C
2 MCBs 16A, 1P, B
Part No. 97598


Receptacle combinations, pre-wired for installation

Enclosure and insert made of **Amaplast**.

Combinations can also be supplied with SCHUKO® type receptacles 16A, 230V, 2P+E or French/Belgian, British, Danish and Swiss standards:




Protection type Δ IP 44

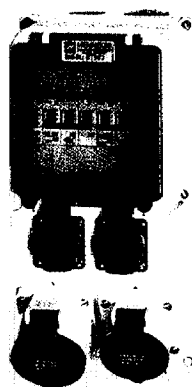


1 CEEform receptacle 16A, 400V, 5P
 1 CEEform receptacle 32A, 400V, 5P
 2 SCHUKO® type receptacles
 16A, 230V, 2P+E
 Fuse/protection:
 1 MCB 16A, 3P, K
 1 MCB 32A, 3P, K
 2 MCBs 16A, 1P, B
 Preferably with connection for
 2 cables of up to 5x25 mm²
Part No. 96151




As above, but with
 fuse/protection:
 1 MCB 16A, 3P, C
 1 MCB 32A, 3P, C
 2 MCBs 16A, 1P, B
Part No. 97983

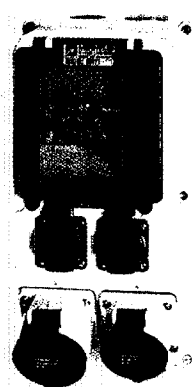


1 CEEform receptacle 16A, 400V, 5P
 1 CEEform receptacle 32A, 400V, 5P
 2 SCHUKO® type receptacles
 16A, 230V, 2P+E
 Fuse/protection:
 1 MCB 16A, 3P, D
 1 MCB 32A, 3P, D
 2 MCBs 16A, 1P, B
 Preferably with connection for
 2 cables of up to 5x25 mm²
Part No. 90111

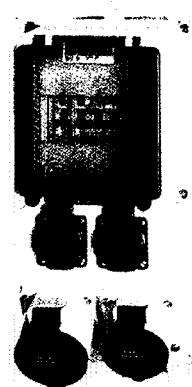


1 CEEform receptacle 16A, 400V, 5P
 1 CEEform receptacle 32A, 400V, 5P
 2 SCHUKO® type receptacles
 16A, 230V, 2P+E
 Fuse/protection:
 1 MCB 16A, 3P, C
 2 MCBs 16A, 1P, B
 Preferably with connection for
 2 cables of up to 5x25 mm²
Part No. 96745

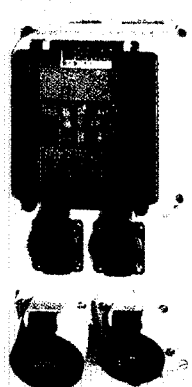


1 CEEform receptacle 16A, 400V, 5P
 1 CEEform receptacle 32A, 400V, 5P
 2 SCHUKO® type receptacles
 16A, 230V, 2P+E
 Fuse/protection:
 1 MCB 16A, 3P, C
 2 MCBs 16A, 1P, B
 1 RCD Δ 40A, I_{ΔN} = 0,03A
Part No. 92498

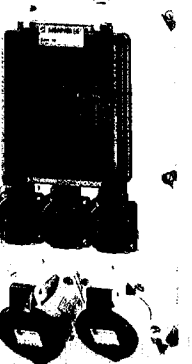

1 CEEform receptacle 16A, 400V, 5P
 1 CEEform receptacle 32A, 400V, 5P
 3 SCHUKO® type receptacles
 16A, 230V, 2P+E
 Fuse/protection:
 1 MCB 16A, 3P, C
 1 MCB 32A, 3P, C
 2 MCBs 16A, 1P, B
 Preferably with connection for
 2 cables of up to 5x25 mm²
Part No. 91541

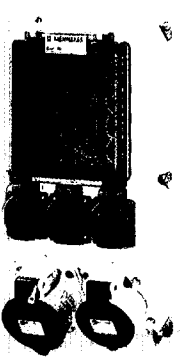

1 CEEform receptacle 16A, 400V, 5P
 1 CEEform receptacle 32A, 400V, 5P
 3 SCHUKO® type receptacles
 16A, 230V, 2P+E
 Fuse/protection:
 1 Neozed D 01, 3P
 1 Neozed D 02, 3P
 3 Neozed D 01, 1P
 Preferably with connection for
 2 cables of up to 5x25 mm²
Part No. 95795

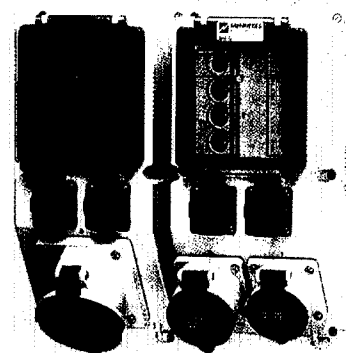

2 Casing

1. 1 CEEform receptacle 63A, 400V, 5P
 2 SCHUKO® type receptacles
 16A, 230V, 2P+E
 Fuse/protection:
 1 Neozed D 02, 3P
 2 Neozed D 01, 1P

2. 1 CEEform receptacle 16A, 400V, 5P
 1 CEEform receptacle 32A, 400V, 5P
 2 SCHUKO® type receptacles
 16A, 230V, 2P+E
 Fuse/protection:
 1 Neozed D 01, 3P
 1 Neozed D 02, 3P
 2 Neozed D 01, 1P
 Preferably with connection for
 2 cables of up to 5x25 mm²

Part No. 97557

